

High profile ball transfer unit


BPLF

For light loads

- **Pressed steel ball transfer unit with mounting plate**
- With 2 or 4 mounting holes for screws or rivets.
(The BPLF25-55-2F has 2 slots rather than 2 holes to accommodate different centre distances)
- For light loads
- Housing made from pressed steel
- With drainage hole and felt seal.
- Orientation: horizontal with ball upwards
- Max. speed: 1m/s
- Working temperature range: -20 to +70°C
- Materials:



BPL:galvanised steel body and steel balls
BPL/SS:stainless steel body and stainless steel
 420 balls

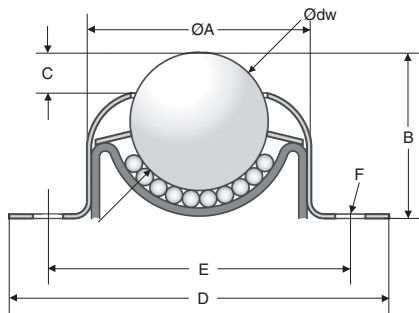

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc. Prix	-10%	-15%	-20%	On request	

Part N°	Ødw ball	ØA	B	C	D	E	F	Carrying capacity (kg)	Weight (kg)	Stock*	Price each 1 to 5
Steel body, steel balls											
BPLF25-45-2F	25,4	45,0	30,4	6,3	69 x 51	55,9 - 60,3	Fente 2 x 5,5 x 7,7	55	0,155	✓	5,84 €
BPLF38-67-4	38,1	66,9	46,2	9,8	76,2 x 76,2	62,7 x 62,7	4 x Ø7,1	115	0,520	-	17,65 €
Stainless steel body / Stainless steel ball											
BPLF25-45-2F/SS	25,4	45,0	30,4	6,3	69 x 51	55,9 - 60,3	Fente 2 x 5,5 x 7,7	55	0,151	✓	15,21 €

*Depending on availability - Dimensions in mm

Our other products



PRF-SCL

Lock for aluminium profile, Lock for sliding doors



BPBF

Ball transfer unit push fit, Heavy



PM3

Worm and wheel set, Machined plastic (delrin)



CQA20

Accessory for adjustment slide-system, 20



SCR

Suction cup threaded insert, Adaptor for insert



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane



CDGamme

Compression spring DIN2095, DIN 2095



PRF_ECL

Nut for aluminium profile, Steel square nut with tab




CHMR50

Worm and wheel gear reducer, up to 107



BSB

 Ballscrew bearing unit, Support



GMK17_P

Flat Guide, Flat guide for conical profile



CHA_GC_9SS

Stainless steel garnet hinge, To be welded

Complementary products



BPL

Ball transfer unit light duty, Light



BPLE

Ball transfer unit push fit, Light



BPLF

Ball transfer unit light duty, Light