


- **Positioning and locating screw**
- Slotted set screw
- Working temperature : -30°C to +50°C
- Materials :
  - Body : plastic
  - Ball : stainless steel or plastic
  - Spring : Stainless steel 1,4310

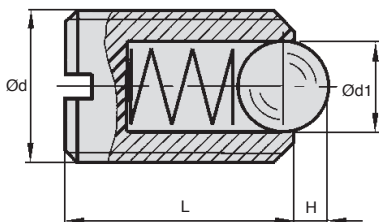

Ball Stainless steel or Delrin



**INCREASED STOCK**

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Ød	Ød1	L	H	Pressure (N)		Stock*	Price each 1 to 5
					Initial	final		
<b>Stainless steel ball</b>								
BPM6Z/SS	M6	3,5	14	1,0	9	13	✓	1,61 €
BPM8Z/SS	M8	5,0	16	1,5	15	30	✓	1,98 €
BPM10Z/SS	M10	6,0	19	2,0	20	40	✓	2,34 €
<b>Plastic ball</b>								
BPM6Z/P	M6	3,5	14	1,0	9	13	✓	1,85 €
BPM8Z/P	M8	5,0	16	1,5	15	30	✓	2,30 €
BPM10Z/P	M10	6,0	19	2,0	20	40	-	2,53 €

Dimensions in mm

## Our other products



DCA

Suction cup, 1.5 bellows, nitrile



CHAsb28

Roll of hinge without pin, Plastic hinge



GE1006

Elastic ringed latch, Hooks into a slot



SF\_ZZ

Deep groove ball bearing, Stainless steel



T5\_11

T type timing pulley, T5 aluminium



CLQassortiment

Assorted feeler strips, Assorted feeler strips



SHSS

Shoulder screw stainless steel 416, Pre-treated 416 stainless steel



GAL48\_OMNI

Omni-directional roller, Omni-directional



CLSCLP\_SS

Clevis components, short version, Stainless steel - short



LVT

Miniature motorised actuator 4A, 4 ampers



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



BLHB40

Right angled gearbox, bored shafts, up to 10.3 Nm

## Complementary products



BPM-Z

Plastic slotted spring plunger with ball tip, Plastic body + staine...



BPM\_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



BLM

Spring loaded plunger with ball tip, Plastic body



BPM

Slotted spring plunger with ball tip, Steel