


- Positioning and locating screw
- Slotted set screw
- Working temperature : -30°C to +50°C
- Materials :
 - Body : plastic
 - Ball : stainless steel or plastic
 - Spring : Stainless steel 1,4310



Ball Stainless steel or Delrin

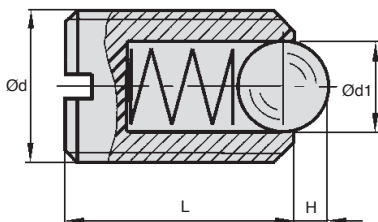

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request


Part number	Ød	Ød1	L	H	Pressure (N)		Price each
					Initial	final	1 to 5
Stainless steel ball							
BPM6Z/SS	M6	3,5	14	1,0	9	13	1,61 €
BPM8Z/SS	M8	5,0	16	1,5	15	30	1,98 €
BPM10Z/SS	M10	6,0	19	2,0	20	40	2,34 €
Plastic ball							
BPM6Z/P	M6	3,5	14	1,0	9	13	1,85 €
BPM8Z/P	M8	5,0	16	1,5	15	30	2,30 €
BPM10Z/P	M10	6,0	19	2,0	20	40	2,53 €

Dimensions in mm

Our other products



PF45
Worm and wheel gear reducer, up to 40 Nm

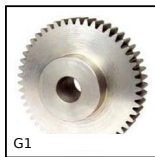

G1
Steel spur gear, Steel 20NCD2



GSI
Stainless steel gas spring, Stainless steel



V3RA_PTR
3-spoked handwheel with foldable handle, Polyamide



RTN
BoWex® curved tooth gear coupling, Nylon



BLHB40
Right angled gearbox, bored shafts, up to 10.3 Nm



SNG
Stainless/Polymer pillow block bearing, Cast iron - Split pillow



TM_CTM_CTF
Suction cup threaded insert, Insert for suction cup - Tread click-in



PPD
Indexing plunger for sheets, For sheet



GDR880
Straight track for slat top chain, Ranges 880



GE
Toggle latches, Miniature



CHB
Single output shaft, For CHB gearbox

Complementary products



BPM-Z
Plastic slotted spring plunger with ball tip, Plastic body + plastic...



BPM_LOK
Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



BPM_LOK
Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...



BLM
Spring loaded plunger with ball tip, Stainless steel body