



- **Positioning and locating screw**
- Slotted set screw
- Working temperature : -30°C to +50°C
- Materials :
 - Body : plastic
 - Ball : stainless steel or plastic
 - Spring : Stainless steel 1,4310

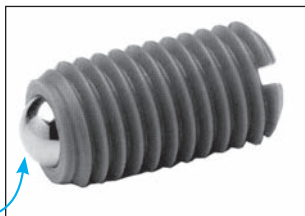

Ball Stainless steel or Delrin

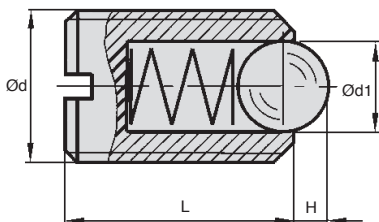

INCREASED STOCK

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Ød	Ød1	L	H	Pressure (N)		Stock*	Price each 1 to 5
					Initial	final		
Stainless steel ball								
BPM6Z/SS	M6	3,5	14	1,0	9	13	✓	1,61 €
BPM8Z/SS	M8	5,0	16	1,5	15	30	✓	1,98 €
BPM10Z/SS	M10	6,0	19	2,0	20	40	✓	2,34 €
Plastic ball								
BPM6Z/P	M6	3,5	14	1,0	9	13	✓	1,85 €
BPM8Z/P	M8	5,0	16	1,5	15	30	✓	2,30 €
BPM10Z/P	M10	6,0	19	2,0	20	40	-	2,53 €

Dimensions in mm

Our other products



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



 
BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



VTHA

Magnetic screw with hexagonal head, Steel



LAT2

2A motorised linear actuator, 2 amperes



MHPGR

Arm with folding rotating handle,



PTGR

Tensioner pulley, For round belts



PRF_ER

Joining bar for aluminium profile, Joint bar



PGR

Folding revolving handle for handwheel, Folding



DOMI30

Connecting kits, XZ linking kit




PLM-SC

Magnetic stud with central countersunk



PRF1932

 Standard aluminium profile, 19 x 32 mm



B

Steel bevel gear, 1:1

Complementary products



BPM-Z

Plastic slotted spring plunger with ball tip, Plastic body + stainle...



BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



BLM

Spring loaded plunger with ball tip, Plastic body



BPM

Slotted spring plunger with ball tip, Steel