


- **Positioning and locating screw**
- Slotted set screw
- Working temperature : -30°C to +50°C
- Materials :
  - Body : plastic
  - Ball : stainless steel or plastic
  - Spring : Stainless steel 1,4310

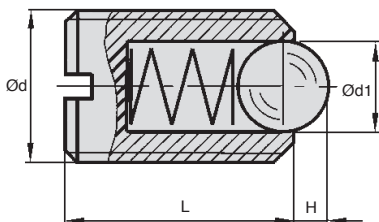

Ball Stainless steel or Delrin



**INCREASED STOCK**

### DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Ød	Ød1	L	H	Pressure (N)		Stock*	Price each 1 to 5
					Initial	final		
<b>Stainless steel ball</b>								
BPM6Z/SS	M6	3,5	14	1,0	9	13	✓	1,61 €
BPM8Z/SS	M8	5,0	16	1,5	15	30	✓	1,98 €
BPM10Z/SS	M10	6,0	19	2,0	20	40	✓	2,34 €
<b>Plastic ball</b>								
BPM6Z/P	M6	3,5	14	1,0	9	13	✓	1,85 €
BPM8Z/P	M8	5,0	16	1,5	15	30	✓	2,30 €
BPM10Z/P	M10	6,0	19	2,0	20	40	-	2,53 €

Dimensions in mm

## Our other products



 
CHINV

Invisible hinge,  
Invisible - 90° opening



ACL

Joints for aluminium  
profile, Variable angle  
hinge



IN1

Internal gear,  
Machined plastic  
(delrin)



HG6

Steel spur gear, Steel  
20NCD2



 
SSG2\_304L

Stainless steel spur  
gear, Stainless steel  
304L



UCP PBT

Stainless/Polymer  
pillow block bearing,  
Polymer and stainless  
steel



M1

Worm and wheel set,  
Machined plastic  
(delrin)



HCV

V-rail guidance  
Simple Select®  
system, on rail



CHAFR-MINI

Miniature friction  
hinge, Friction



 
DILC

Indexing plunger with  
cam, with cam



RHTplss

High Temperature  
Castor, up to 200kg



PRF4545r90

Standard aluminium  
profile, 45 x 45 mm -  
R90°

## Complementary products



BPM-Z

Plastic slotted spring  
plunger with ball tip,  
Plastic body + plastic...



BPM\_LOK

Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -  
Steel



BPM\_LOK

Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -  
Stainless ...



BLM

Spring loaded plunger  
with ball tip, Stainless  
steel body