


- **Positioning and locating screw**
- Slotted set screw
- Working temperature : -30°C to +50°C
- Materials :
 - Body : plastic
 - Ball : stainless steel or plastic
 - Spring : Stainless steel 1,4310

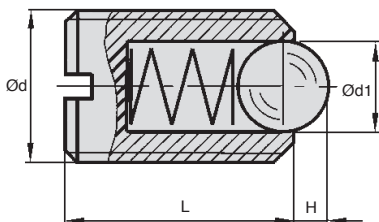

Ball Stainless steel or Delrin



INCREASED STOCK

DISCOUNTS

Qty	1+	6+	20+	50+	100+	250+	400+
Disc.	List	-5%	-10%	-15%	-20%	-25%	On request

Part number	Ød	Ød1	L	H	Pressure (N)		Stock*	Price each 1 to 5
					Initial	final		
Stainless steel ball								
BPM6Z/SS	M6	3,5	14	1,0	9	13	✓	1,61 €
BPM8Z/SS	M8	5,0	16	1,5	15	30	✓	1,98 €
BPM10Z/SS	M10	6,0	19	2,0	20	40	✓	2,34 €
Plastic ball								
BPM6Z/P	M6	3,5	14	1,0	9	13	✓	1,85 €
BPM8Z/P	M8	5,0	16	1,5	15	30	✓	2,30 €
BPM10Z/P	M10	6,0	19	2,0	20	40	-	2,53 €

Dimensions in mm

Our other products



MC
Self-compensating shock-absorber, Self-compensating - without adjust...



PRF JL6
Lip seal for panel, Door seal - Ø 6mm



ACAss
Stainless steel splined shaft, Stainless steel



LC
Friction clutch, 190 to 1800 Nm



NSA
Adjustable clamp, Articulated



DB
Steel bevel gear, 2:1



CHAsb28
Roll of hinge without pin, Plastic hinge



CHAGC-AL
Screw-in garnet hinge, Screw-on



SSB
Stainless steel bevel gear, 1:1



SHA
Handwheel without handle, Polyamide



HAR9
Captive C washer, DIN 6371



MAX22
Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm

Complementary products



BPM-Z
Plastic slotted spring plunger with ball tip, Plastic body + staine...



BPM_LOK
Long-Lok slotted spring plunger with ball tip, LONG-LOK - Steel



BLM
Spring loaded plunger with ball tip, Plastic body



BPM
Slotted spring plunger with ball tip, Steel