





## BPP

## 2 mounting points

- Pressed sheet flanged bearing
- Material : steel

### Uses

- Simple mounted bearing for light loads

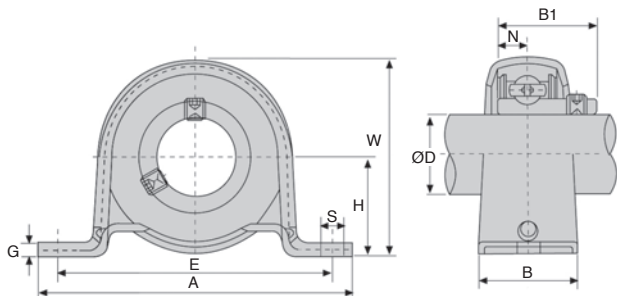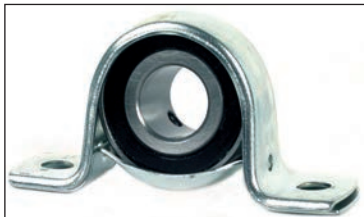

Part number	Load (kN)	
	Dynamic C	Static Co
BPP201	9,2	4,48
BPP202	9,2	4,48
BPP203	9,2	4,48
BPP204	12,2	6,30
BPP205	13,3	7,46
BPP206	18,5	10,80
BPP207	24,5	14,60

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP201	12	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,39 €
BPP202	15	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,44 €
BPP203	17	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,79 €
BPP204	20	25,4	98	76	32	9,5	3,2	50,5	M8	25	7,0	0,23	✓	10,93 €
BPP205	25	28,6	108	86	32	11,5	4,0	56,6	M10	27	7,5	0,28	✓	11,55 €
BPP206	30	33,3	117	95	38	11,5	4,0	66,3	M10	30	8,0	0,47	✓	15,86 €
BPP207	35	39,7	129	106	42	11,5	4,6	78,0	M10	32	8,5	0,57	✓	18,59 €


\*Depending on availability - Dimensions in mm

## Our other products



PR105

 Articulated foot Ø103,  
Ø 103



M1

Worm and wheel set,  
Machined plastic  
(delrin)



WSRM

Cylindrical polymer  
nut, Polymer  
(Iglidur®) - 1 thread



WW10

Drylin® W slide, slide  
assembly



BAN

Angular clamp,  
Universal



GLT3-46

Telescopic drawer,




PTAF100-PAMF100

Articulated fixable  
foot with pressed  
base Ø100, Ø 100



GP

 Spring loaded toggle  
latch, Standard  
(GP22-GP23)




VKM

Square steel nut,  
Steel - 1 thread



M0

 Worm and wheel set,  
Hardened steel



SLVHlok

Vertical toggle clamp,  
Vertical toggle clamp /  
horizontal foot



ACLAPA

Magnetic stop for  
aluminium profile,  
Magnetic stop

## Complementary products



BPF

Sheet steel flanged  
bearing for light  
loads, Sheet steel



BPFL

Sheet steel flanged  
bearing for light  
loads, Sheet steel



BPPss

Pressed stainless  
steel pillow block,  
Stainless steel