





## BPP

## 2 mounting points

- Pressed sheet flanged bearing
- Material : steel

### Uses

- Simple mounted bearing for light loads

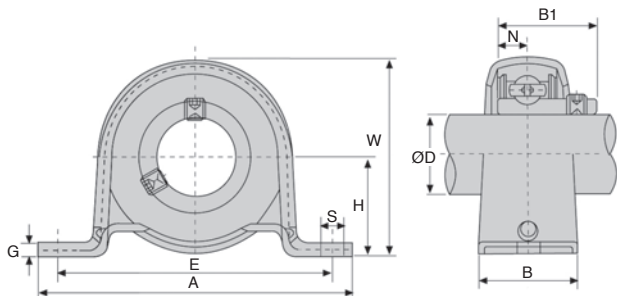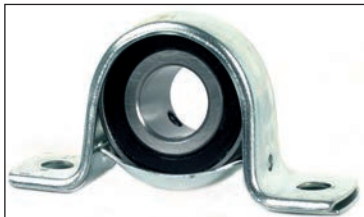

Part number	Load (kN)	
	Dynamic C	Static Co
BPP201	9,2	4,48
BPP202	9,2	4,48
BPP203	9,2	4,48
BPP204	12,2	6,30
BPP205	13,3	7,46
BPP206	18,5	10,80
BPP207	24,5	14,60

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP201	12	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,39 €
BPP202	15	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,44 €
BPP203	17	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,79 €
BPP204	20	25,4	98	76	32	9,5	3,2	50,5	M8	25	7,0	0,23	✓	10,93 €
BPP205	25	28,6	108	86	32	11,5	4,0	56,6	M10	27	7,5	0,28	✓	11,55 €
BPP206	30	33,3	117	95	38	11,5	4,0	66,3	M10	30	8,0	0,47	✓	15,86 €
BPP207	35	39,7	129	106	42	11,5	4,6	78,0	M10	32	8,5	0,57	✓	18,59 €

\*Depending on availability - Dimensions in mm

## Our other products



HTD14M\_55

HTD Heavy duty timing pulley, HTD14 Steel




VDS CB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...



CHA135

Screwed hinge, 135 degrees

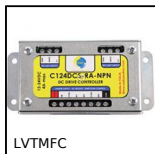

LVTMFC

Device for controlling limit switches, For mini-actuator LVT



DGSA

Male rod ends , Steel / steel - Economy range



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



GLT3-46A

Telescopic drawer with damper,



BHEX

Hexagonal cap, Black technopolymer



GET-AL

Jaw coupling, economy range, Aluminium



G0

Steel spur gear, Steel 20NCD2



RPCtC

Swivel castor with central hole, Steel - Polyamide



RPCtCcs

Swivel castor with central hole, Stainless steel - Polyamide - with ...

## Complementary products



BPF

Sheet steel flanged bearing for light loads, Sheet steel



BPFL

Sheet steel flanged bearing for light loads, Sheet steel



BPPss

Pressed stainless steel pillow block, Stainless steel