





BPP

2 mounting points

- Pressed sheet flanged bearing
- Material : steel

Uses

- Simple mounted bearing for light loads

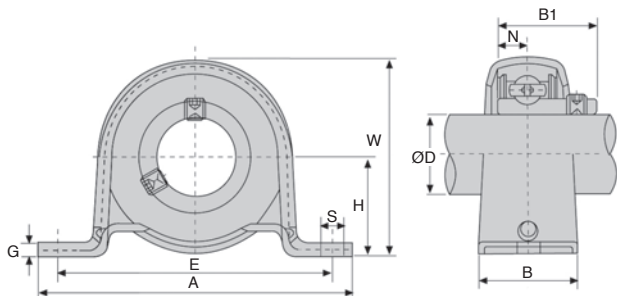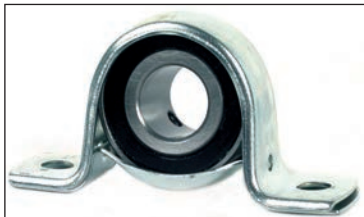

Part number	Load (kN)	
	Dynamic C	Static Co
BPP201	9,2	4,48
BPP202	9,2	4,48
BPP203	9,2	4,48
BPP204	12,2	6,30
BPP205	13,3	7,46
BPP206	18,5	10,80
BPP207	24,5	14,60

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP201	12	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,39 €
BPP202	15	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,44 €
BPP203	17	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	9,79 €
BPP204	20	25,4	98	76	32	9,5	3,2	50,5	M8	25	7,0	0,23	✓	10,93 €
BPP205	25	28,6	108	86	32	11,5	4,0	56,6	M10	27	7,5	0,28	✓	11,55 €
BPP206	30	33,3	117	95	38	11,5	4,0	66,3	M10	30	8,0	0,47	✓	15,86 €
BPP207	35	39,7	129	106	42	11,5	4,6	78,0	M10	32	8,5	0,57	✓	18,59 €

*Depending on availability - Dimensions in mm

Our other products



PGR

Folding revolving handle for handwheel, Folding



HSE-HSB

Hexagonal spacer, Brass



VELM6

Screw-on base for hook-and-loop strip, Polyamide



RPCpl

Swivel castor with double brake, Steel - Polyamide



PCS37K

Chain sprocket with hardened teeth, 9.525mm (DIN06B-1)



T39_T49

Extension spring in metre length stainless steel, by the metre




ACL-FPA

Panel mounting block for aluminium structures, Angular connector



BH01

 Single housed bearing, Bearing fitted with adhesive



RPP5

RPP heavy duty timing belt, RPP5



BTC_M

End cap with threaded insert for square tube, With threaded insert



HSSss

 
Stainless steel shoulder screw ISO7379, Stainless



CHT

Asynchronous AC motor 0.12 to 0.22kW, 0.12 to 0.22kW

Complementary products



BPF

Sheet steel flanged bearing for light loads, Sheet steel



BPFL

Sheet steel flanged bearing for light loads, Sheet steel



BPPss

Pressed stainless steel pillow block, Stainless steel