

Ball transfer unit in blue certified plastic

Suitable for foodstuff sector

BPPEBLU




- The ball transfer units are made of a certified blue plastic which is suitable for use in the foodstuff sector
- Press-in assembly
- Conveying speed up to 1.5 m/s
- Foodstuff conform: Food Grade, EU Regulation 1935/2004, EU Regulation 10/2011
- Material :
 - Housing and cap POM
 - Bearing ball stainless steel
 - Load ball stainless steel or plastic
- Temperature range: -30 °C to +50 °C (up to +30°C with plastic load balls)

Advantages

- The ball transfer units are equipped with a gap-free and sealed cap, which prevents the formation of soiled edge
- The dirt holes underneath the housing enable particularly easy cleaning of the ball transfer units



Food industry
NEW!

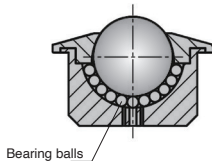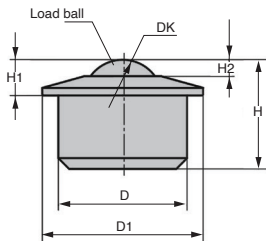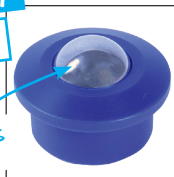


DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-15%	On request

Part number	ØD	ØD1	ØDK	H	H1	H2	Load rating C (kg)	Price each 1 to 5
Load ball in POM								
BPPE15-24/PP/BLU	24±0,1	31±0,2	15,875	20,5±0,2	9,5±0,2	4,5	20	
BPPE22-36/PP/BLU	36±0,1	45±0,2	22,225	30,5±0,2	10±0,2	4,5	25	
BPPE30-45/PP/BLU	45±0,1	55±0,1	30,000	37±0,1	14±0,1	5,5	35	
BPPE45-62/PP/BLU	62±0,1	75±0,1	44,500	53,5±0,1	19±0,1	9,0	50	
Load ball in stainless steel								
BPPE15-24/SS/BLU	24±0,1	31±0,2	15,875	20,5±0,2	9,5±0,2	4,5	20	
BPPE22-36/SS/BLU	36±0,1	45±0,2	22,225	30,5±0,2	10±0,2	4,5	25	
BPPE30-45/SS/BLU	45±0,1	55±0,1	30,000	37±0,1	14±0,1	5,5	35	
BPPE45-62/SS/BLU	62±0,1	75±0,1	44,500	53,5±0,1	19±0,1	9,0	50	

All dimensions in mm.

Our other products

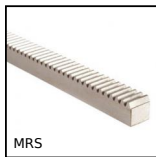

MRS

Stainless steel metric section rack, Stainless steel



BC3

Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



GLT3-46A

Telescopic drawer with damper,



SSDB

Stainless steel bevel gear, 2:1



TPEf

Castor for aluminium profile, Fixed



 
RBNpl

Fixed castor with plate, Steel - rubber



T10_21_AL

T type timing pulley, Economy range - T10 aluminium



M0

Wormwheel, Machined plastic (delrin)




ACA

Steel splined shaft, Steel



CQA20

 Accessory for adjustment slide-



BMF

Knurled knob - female, Knurled -



SH0

Parallel axis helical gear, Steel 20NCD2

Complementary products



BPPE

Ball transfer unit push fit, Light



BPPE

Ball transfer unit push fit, Light



BPPE

Ball transfer unit push fit, Light



BPHF

Ball transfer unit push fit, Heavy