

Pressed stainless steel bearing for light loads

2 mounting holes


BPPSS

- Pressed sheet steel housing
- Material: stainless steel

Application

- Mounting a simple bearing, suitable for light loads only

NEW:
stainless steel
range

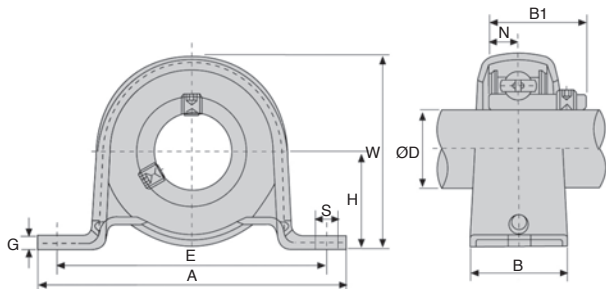

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each
														1 to 5
BPP204/SS	20	25,4	98	76	32	9	3,2	50	M8	25	7	0,22	✓	18,10 €
BPP205/SS	25	28,6	108	86	32	11	4	56	M10	27	7,5	0,29	✓	24,19 €
BPP206/SS	30	33,3	117	95	38	11	4	66	M10	30	8	0,43	✓	27,74 €
BPP207/SS	35	39,7	129	106	42	11	5	78	M10	32	8,5	0,63	-	52,39 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

99

Our other products



J64

Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - In-line



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools



PRF_ER

Joining bar for aluminium profile, Joint bar



CLQ

12.7mm wide steel feeler strip on rolls, Feeler strip on rolls



VCMB

Dual-thread screw wood/metal, Steel



BAC105

Storage bin, 8mm




PENC

Recessed handle, clip-in



CHMR110

 Worm and wheel gear reducer, up to 980 Nm



PRF_LIS

Door seal for aluminium profile, Black NBR



H3

Crossed helical gear crossed axis at 90°, Steel 20NCD2



DOMI30

Domino 30 adjustable slide, Slide DOMILINE 30



RBNtc

Swivel castor with central hole, Steel - rubber - with double brake

Complementary products



BPFss

Pressed stainless steel flange bearing, Stainless steel



BPFLLS

Pressed stainless steel flange bearing, Stainless steel



BPP

Pressed steel flanged bearing for light loads, Sheet steel



UCP_SS

Stainless steel pillow block bearing, Stainless steel