

Pressed stainless steel bearing for light loads

2 mounting holes


BPPSS

- Pressed sheet steel housing
- Material: stainless steel

Application

- Mounting a simple bearing, suitable for light loads only

NEW:
stainless steel
range

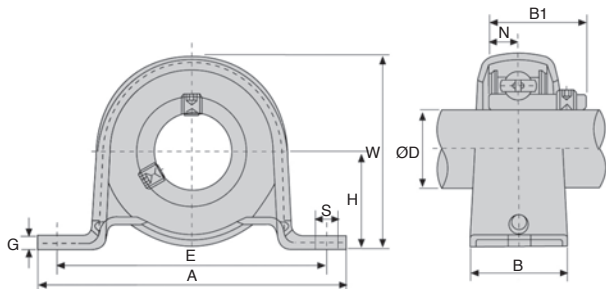

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP204/SS	20	25,4	98	76	32	9	3,2	50	M8	25	7	0,22	✓	18,10 €
BPP205/SS	25	28,6	108	86	32	11	4	56	M10	27	7,5	0,29	✓	24,19 €
BPP206/SS	30	33,3	117	95	38	11	4	66	M10	30	8	0,43	✓	27,74 €
BPP207/SS	35	39,7	129	106	42	11	5	78	M10	32	8,5	0,63	-	52,39 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

99

Our other products



ADL_M
Male eye bolt
conforms to DIN580,
Steel



 
MHXred
Reducing sleeve
male/female,
Hexagonal - stainless
steel



SCE
U-shaped cable
clamp, Steel



PLM-SC
Magnetic stud with
threaded hole, With
threaded hole



KS
Keysteel, Stainless
steel - Keystock



RBG
Wheel, Grey rubber -
Polypropylene rim




TPEpbd
Castor for aluminium
profile, Swivel with
brake



CHB
Single output shaft,
For CHB gearbox



 NDS20
Double cross clamp,
Parallel



PX_PO
Carrying handle, back-
parallel



PM2
Worm and wheel set,
Hardened steel



BEF
Bearing housing for
miniature ballscrew,
Bearing housing

Complementary products



BPFss
Pressed stainless
steel flange bearing,
Stainless steel



BPFLLss
Pressed stainless
steel flange bearing,
Stainless steel



BPP
Pressed steel flanged
bearing for light
loads, Sheet steel



UCP_SS
Stainless steel pillow
block bearing,
Stainless steel