

# Pressed stainless steel bearing for light loads

2 mounting holes


BPPSS

- Pressed sheet steel housing
- Material: stainless steel

## Application

- Mounting a simple bearing, suitable for light loads only

**NEW:**  
stainless steel  
range

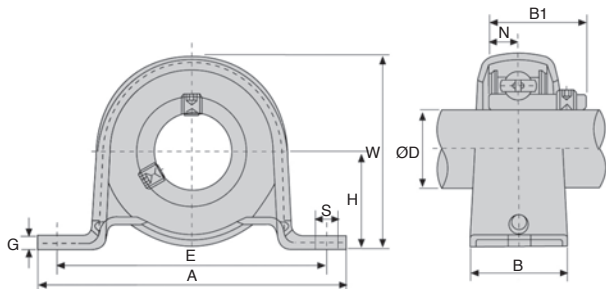

## DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP204/SS	20	25,4	98	76	32	9	3,2	50	M8	25	7	0,22	✓	18,10 €
BPP205/SS	25	28,6	108	86	32	11	4	56	M10	27	7,5	0,29	✓	24,19 €
BPP206/SS	30	33,3	117	95	38	11	4	66	M10	30	8	0,43	✓	27,74 €
BPP207/SS	35	39,7	129	106	42	11	5	78	M10	32	8,5	0,63	-	52,39 €

Dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

**HPC** SUPPLEMENT 2019

99

## Our other products



Rod end, Stainless steel / PTFE



Eye bolt, Stainless steel



Gas spring, Steel



T-Clip - Aluminium profile attachment, Magnetic object holder



Actuator guide kit, Short bearing



Closing system, Quick fitting, self locking door lock



Trapezoidal rolled leadscrew, Medium carbon steel - 1 thread



Captive C washer, DIN 6371



Box set of Nitrile O-rings, 18.00 x 2.00mm to 50.00 x



Crossed helical gear - precision range, 20NCD2 case



Moulded plastic bevel gear (nylon), 3:1



Dowel pin, Boxed set - hitch

 
## Complementary products



Flange bearing, Stainless steel



Flange bearing, Stainless steel



Pillow block, Sheet steel



Pillow block, Stainless steel