

Stock Pla End cap for round tube with threaded insert

Black plastic

BPTRM


- Materials:
Cap: Glass reinforced polyamide
Insert: Nickel brass

Option

- Stainless steel insert

Info.

- For static application only

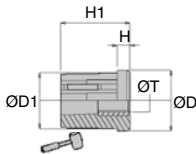

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØT	ØD	ØD1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each
									1 to 59
BPTR30/1-M10	M10	30	28,5	6	35	3200	30x1x28	-	
BPTR30/1-M12	M12	30	28,5	6	35	3200	30x1x28	-	
BPTR30/1-M14	M14	30	28,5	6	35	3200	30x1x28	-	
BPTR30/1-M16	M16	30	28,5	6	35	3200	30x1x28	✓	
BPTR38/1,5-M10	M10	38	35,5	8	43	5500	38x1,5x35	✓	
BPTR38/1,5-M12	M12	38	35,5	8	43	5500	38x1,5x35	-	
BPTR38/1,5-M14	M14	38	35,5	8	43	5500	38x1,5x35	-	
BPTR38/1,5-M16	M16	38	35,5	8	43	5500	38x1,5x35	-	
BPTR42/1,5-M10	M10	42	39,5	8	42	6500	42x1,5x39	-	
BPTR42/1,5-M12	M12	42	39,5	8	42	6500	42x1,5x39	✓	
BPTR42/1,5-M14	M14	42	39,5	8	42	6500	42x1,5x39	-	
BPTR42/1,5-M16	M16	42	39,5	8	42	6500	42x1,5x39	-	
BPTR42/1,5-M20	M20	42	39,5	8	42	6500	42x1,5x39	-	
BPTR48/1,5-M10	M10	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M12	M12	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M14	M14	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M16	M16	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M20	M20	48	45,5	11	49	8000	48x1,5x45	-	
BPTR50/1,5-M12	M12	50	47,5	11	49	8500	50x1,5x47	-	
BPTR50/1,5-M14	M14	50	47,5	11	49	8500	50x1,5x47	-	
BPTR50/1,5-M16	M16	50	47,5	11	49	8500	50x1,5x47	-	
BPTR50/1,5-M20	M20	50	47,5	11	49	8500	50x1,5x47	-	
BPTR60/1,5-M14	M14	60	57,5	12	50	10000	60x1,5x57	✓	
BPTR60/1,5-M16	M16	60	57,5	12	50	10000	60x1,5x57	-	
BPTR60/1,5-M20	M20	60	57,5	12	50	10000	60x1,5x57	-	
BPTR60/1,5-M24	M24	60	57,5	12	50	10000	60x1,5x57	-	
BPTR60/2-M14	M14	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2-M16	M16	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2-M20	M20	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2-M24	M24	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2,5-M14	M14	60	55,5	12	50	10000	60x2,5x55	-	
BPTR60/2,5-M16	M16	60	55,5	12	50	10000	60x2,5x55	-	
BPTR60/2,5-M20	M20	60	55,5	12	50	10000	60x2,5x55	-	
BPTR60/2,5-M24	M24	60	55,5	12	50	10000	60x2,5x55	-	

On request


*Depending on availability - Dimensions in mm

Our other products



M0

Worm and wheel set,
Non hardened steel

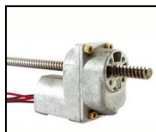

LAT1

1A motorised linear
actuator, 1 ampere



CHAM527055

Marine hinge for
welding/screw
mounting, Marine



ZG0

Plastic spur gear,
Machined plastic
(delrin)



KB_WW

Closed linear
precision bearing,
Economy range



MPE

Hexagonal spacer,
Steel



NK1A

Combined bearing
with inner ring, Axial
load in one direction



G01

Single universal joint,
Normal duty



PSG35

Spur gear - precision
range, Stainless steel
316



BPM_LOK

Long-Lok slotted
spring plunger with
ball tip, LONG-LOK -



M0

Worm and wheel set,
Unhardened steel



SVT_CH

Screwjack - pivot
mounting, Pivoting
bracket

Complementary products



BTC_M

End cap with threaded
insert for square tube,
With threaded insert



BPTR

End cap for round
tube, Standard