

End cap for round tube with threaded insert Pla


BPTR_M

Black plastic

- Materials:

Cap: Glass reinforced polyamide

Insert: Nickel brass

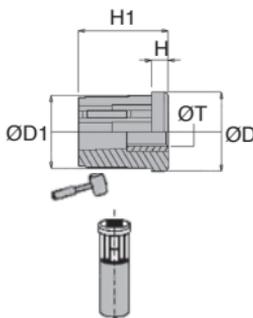

Option

- Stainless steel insert

Info.

- For static application only

Part number	ØT	ØD	ØD1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each 1 to 59
BPTR30/1-M10	M10	30	28,5	6	35	3200	30x1x28		On request
BPTR30/1-M12	M12	30	28,5	6	35	3200	30x1x28		
BPTR30/1-M14	M14	30	28,5	6	35	3200	30x1x28		
BPTR30/1-M16	M16	30	28,5	6	35	3200	30x1x28		
BPTR38/1,5-M10	M10	38	35,5	8	43	5500	38x1,5x35		
BPTR38/1,5-M12	M12	38	35,5	8	43	5500	38x1,5x35		
BPTR38/1,5-M14	M14	38	35,5	8	43	5500	38x1,5x35		
BPTR38/1,5-M16	M16	38	35,5	8	43	5500	38x1,5x35		
BPTR42/1,5-M10	M10	42	39,5	8	42	6500	42x1,5x39		
BPTR42/1,5-M12	M12	42	39,5	8	42	6500	42x1,5x39		
BPTR42/1,5-M14	M14	42	39,5	8	42	6500	42x1,5x39		
BPTR42/1,5-M16	M16	42	39,5	8	42	6500	42x1,5x39		
BPTR42/1,5-M20	M20	42	39,5	8	42	6500	42x1,5x39		
BPTR48/1,5-M10	M10	48	45,5	11	49	8000	48x1,5x45		
BPTR48/1,5-M12	M12	48	45,5	11	49	8000	48x1,5x45		
BPTR48/1,5-M14	M14	48	45,5	11	49	8000	48x1,5x45		
BPTR48/1,5-M16	M16	48	45,5	11	49	8000	48x1,5x45		
BPTR48/1,5-M20	M20	48	45,5	11	49	8000	48x1,5x45		
BPTR50/1,5-M12	M12	50	47,5	11	49	8500	50x1,5x47		
BPTR50/1,5-M14	M14	50	47,5	11	49	8500	50x1,5x47		
BPTR50/1,5-M16	M16	50	47,5	11	49	8500	50x1,5x47		
BPTR50/1,5-M20	M20	50	47,5	11	49	8500	50x1,5x47		
BPTR60/1,5-M14	M14	60	57,5	12	50	10000	60x1,5x57		
BPTR60/1,5-M16	M16	60	57,5	12	50	10000	60x1,5x57		
BPTR60/1,5-M20	M20	60	57,5	12	50	10000	60x1,5x57		
BPTR60/1,5-M24	M24	60	57,5	12	50	10000	60x1,5x57		
BPTR60/2-M14	M14	60	56,5	12	50	10000	60x2x56		
BPTR60/2-M16	M16	60	56,5	12	50	10000	60x2x56		
BPTR60/2-M20	M20	60	56,5	12	50	10000	60x2x56		
BPTR60/2-M24	M24	60	56,5	12	50	10000	60x2x56		
BPTR60/2,5-M14	M14	60	55,5	12	50	10000	60x2,5x55		
BPTR60/2,5-M16	M16	60	55,5	12	50	10000	60x2,5x55		
BPTR60/2,5-M20	M20	60	55,5	12	50	10000	60x2,5x55		
BPTR60/2,5-M24	M24	60	55,5	12	50	10000	60x2,5x55		

Dimensions in mm