

Black plastic

BPTRM


- Materials:
Cap: Glass reinforced polyamide
Insert: Nickel brass

Option

- Stainless steel insert

Info.

- For static application only

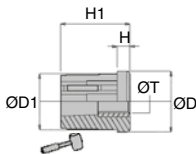

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØT	ØD	ØD1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each
									1 to 59
BPTR30/1-M10	M10	30	28,5	6	35	3200	30x1x28	-	
BPTR30/1-M12	M12	30	28,5	6	35	3200	30x1x28	-	
BPTR30/1-M14	M14	30	28,5	6	35	3200	30x1x28	-	
BPTR30/1-M16	M16	30	28,5	6	35	3200	30x1x28	✓	
BPTR38/1,5-M10	M10	38	35,5	8	43	5500	38x1,5x35	✓	
BPTR38/1,5-M12	M12	38	35,5	8	43	5500	38x1,5x35	-	
BPTR38/1,5-M14	M14	38	35,5	8	43	5500	38x1,5x35	-	
BPTR38/1,5-M16	M16	38	35,5	8	43	5500	38x1,5x35	-	
BPTR42/1,5-M10	M10	42	39,5	8	42	6500	42x1,5x39	-	
BPTR42/1,5-M12	M12	42	39,5	8	42	6500	42x1,5x39	✓	
BPTR42/1,5-M14	M14	42	39,5	8	42	6500	42x1,5x39	-	
BPTR42/1,5-M16	M16	42	39,5	8	42	6500	42x1,5x39	-	
BPTR42/1,5-M20	M20	42	39,5	8	42	6500	42x1,5x39	-	
BPTR48/1,5-M10	M10	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M12	M12	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M14	M14	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M16	M16	48	45,5	11	49	8000	48x1,5x45	-	
BPTR48/1,5-M20	M20	48	45,5	11	49	8000	48x1,5x45	-	
BPTR50/1,5-M12	M12	50	47,5	11	49	8500	50x1,5x47	-	
BPTR50/1,5-M14	M14	50	47,5	11	49	8500	50x1,5x47	-	
BPTR50/1,5-M16	M16	50	47,5	11	49	8500	50x1,5x47	-	
BPTR50/1,5-M20	M20	50	47,5	11	49	8500	50x1,5x47	-	
BPTR60/1,5-M14	M14	60	57,5	12	50	10000	60x1,5x57	✓	
BPTR60/1,5-M16	M16	60	57,5	12	50	10000	60x1,5x57	-	
BPTR60/1,5-M20	M20	60	57,5	12	50	10000	60x1,5x57	-	
BPTR60/1,5-M24	M24	60	57,5	12	50	10000	60x1,5x57	-	
BPTR60/2-M14	M14	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2-M16	M16	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2-M20	M20	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2-M24	M24	60	56,5	12	50	10000	60x2x56	-	
BPTR60/2,5-M14	M14	60	55,5	12	50	10000	60x2,5x55	-	
BPTR60/2,5-M16	M16	60	55,5	12	50	10000	60x2,5x55	-	
BPTR60/2,5-M20	M20	60	55,5	12	50	10000	60x2,5x55	-	
BPTR60/2,5-M24	M24	60	55,5	12	50	10000	60x2,5x55	-	

On request

*Depending on availability - Dimensions in mm

Our other products



CLSCLP_SS

Clevis components, short version, Stainless steel - short range



RHTtcss

High Temperature Castor, up to 200kg



VAP

Magnetic stud with central hole, With central hole



J64

Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - In-line



BABV

Ball lock pins lockable, Stainless steel



MRS

Stainless steel metric section rack, Stainless steel



PR40

Articulated foot Ø40, Ø 40



CQA20

Adjustment slide-system miniature, 20



BWU

Compact precision slide, from 1510 N to



SFWR

End support, Surface mounting



TBEBASE10

Economic mini-table with trapezoidal



MDR

Dee shackle with eye bolt, Steel

Complementary products



BTC_M

End cap with threaded insert for square tube, With threaded insert



BPTR

End cap for round tube, Standard