

Knurled tapped Torque Knob

Adjustable torque

BSC

- **Knurled knob with coloured insert**
- **Materials:**
Dark grey thermoplastic
Tapped insert: black oxidised steel 5.8




Info.

- The required torque is adjusted by means of a screw.
- As soon as this torque is reached, the knurled knob will start to slip.

Options

- Versions with different coloured inserts are available, signal red, dark grey, yellow

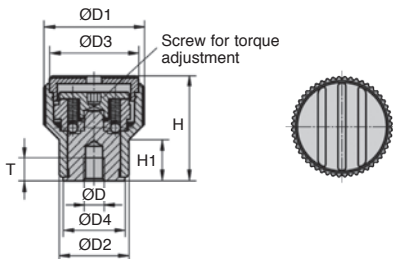

Same tightening torque

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	ØD3	ØD4	H	H1	T	Torque range (Nm)	Price each 1 to 5
Grey insert										
BSC26-M5	M5	26	18	23	16	27	10,5	5	0,1 - 0,3	44,38 €
BSC26-M6	M6	26	18	23	16	27	10,5	6	0,1 - 0,3	44,38 €
BSC34-M6	M6	34	22	31	20	37,5	14,5	10	0,1 - 0,3	48,96 €
BSC34-M8	M8	34	22	31	20	37,5	14,5	14	0,1 - 0,3	48,96 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

141

Our other products



EMR
Fast-locking knurled
nut, Knurled



PML
Solid foot mount for
heavy loads, Ø 100,
120 or 150



HLUMss
Revolving handle for
handwheel, Stainless
steel 316




SRG
Adjustable latch
clamp with strike
plate, Stroke from
96mm to 121,7mm



PSG25S
Spur gear - precision
range, Stainless steel
316



 PW_PWG25
Worm - precision
range, Steel




PRF_TOOL
Assembly key for
aluminium profile,
Assembly key



PRF_CH
Cable-carrier chain for
aluminium profile,
Supplied in metre
lengths



 PM2
Worm and wheel set,
Bronze



RPP5
RPP heavy duty
timing belt, RPP5



LRR
Spring loaded latch,
Spring loaded latch



DOMI120
Domino 120
adjustable slide, Slide
DOMILINE 120

Complementary products



BSCm
Knurled torque knobs
- male, Knurled
threaded torque