

# Knurled tapped Torque Knob

## Adjustable torque

## BSC


- **Knurled knob with coloured insert**
- Materials:
  - Dark grey thermoplastic
  - Tapped insert: black oxidised steel 5.8

### Info.

- The required torque is adjusted by means of a screw.
- As soon as this torque is reached, the knurled knob will start to slip.

### Options

- Versions with different coloured inserts are available, signal red, dark grey, yellow

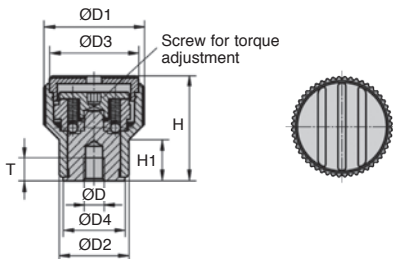

Same tightening torque

### DISCOUNTS

 
Qty	1+	6+	10+	25+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØD2	ØD3	ØD4	H	H1	T	Torque range (Nm)	Price each 1 to 5
<b>Grey insert</b>										
BSC26-M5	M5	26	18	23	16	27	10,5	5	0,1 - 0,3	44,38 €
BSC26-M6	M6	26	18	23	16	27	10,5	6	0,1 - 0,3	44,38 €
BSC34-M6	M6	34	22	31	20	37,5	14,5	10	0,1 - 0,3	48,96 €
BSC34-M8	M8	34	22	31	20	37,5	14,5	14	0,1 - 0,3	48,96 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products



PTR

Idle chain sprocket,  
For standard  
applications



AC

Strike for toggle latch,  
12,13,18 and 20mm



BABpss

301 Stainless steel  
ball pin, Stainless  
steel



ES

Support base (tripod),  
Plastic



DOMI50

Accessories, Plate



ACL-PR

Joining plate for  
aluminium profile,  
Right angled  
connection



SVR15

Screwjack with  
travelling nut, with  
moving nut



AT5courroie

AT type timing belt,  
AT5 Steel cored  
polyurethane



RAM35

Manual bevel  
gearbox, Bevel



UCF\_SS

Stainless steel flanged  
bearing, Stainless  
steel



PCS37K

Chain sprocket with  
hardened teeth,  
9.525mm (DIN06B-1)



MLY\_SS

Stainless steel bow  
shackle with eye bolt,  
Stainless steel

## Complementary products



BSCm

Knurled torque knobs  
- male, Knurled  
threaded torque