

Single rod clip




BSPT

Plastic

- Materials:

Body: reinforced polyamide

Screws: stainless steel 304

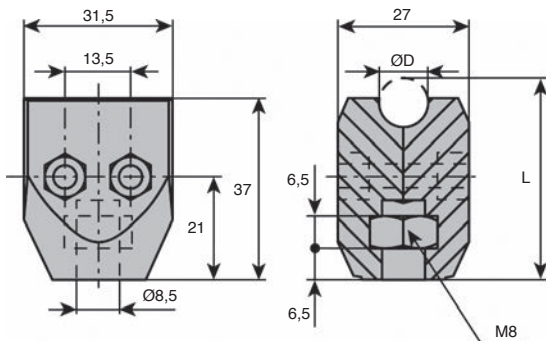

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØD	L	Weight (kg)	Stock*	Price each 1 to 49
BSPT-8	8	40	0,04	-	1,50 €
BSPT-10	10	41	0,04	✓	1,50 €
BSPT-12	12	42	0,04	✓	1,50 €
BSPT-14	14	42	0,04	✓	1,50 €

*Depending on availability - Dimensions in mm

Our other products



SLHVlok

Horizontal toggle clamp, Horizontal toggle clamp / vertical foot



Gal-cardan

Single universal joint eco series, Low duty



PSG15

Spur gear - precision range, Pre-hardened Steel 35NCD6



GE

Toggle latches, Standard



RBGtc

Swivel castor with central hole, Steel - grey rubber



CHTRP

Single and dual output gearboxes, Up to 9,1 Nm



PDD

Actuating plunger, Non-rotating detector shaft



PDD

Actuating plunger, Non-rotating detector shaft



PPS

Lifting ring, Universal threaded



GP

Spring loaded toggle latch, With padlock-holder



ZHBRA

Plastic bevel gear, 1,25:1 2:1 3:1



J53

Spur gear coaxial gearbox, from 0.43 to 1.15 - Inline

Complementary products



GMC_GMK_BR

Guiding profile clamp, Flat or rounded



APB_F

Adjusting rod for clamp - Male, Threaded



SDG

Adjustable guide support bracket, Plastic



SDG_SS

Universal adjustable guide support bracket, Stainless steel