

Single rod clip




BSPT

Plastic

- Materials:

Body: reinforced polyamide

Screws: stainless steel 304

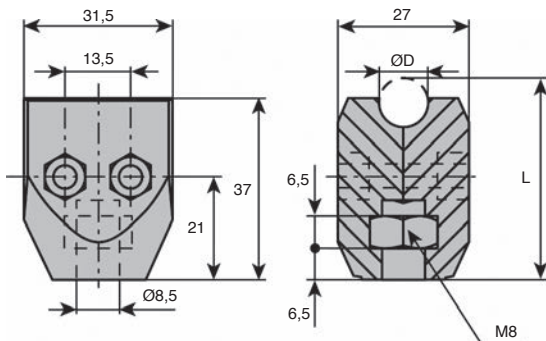

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØD	L	Weight (kg)	Stock*	Price each 1 to 49
BSPT-8	8	40	0,04	-	1,50 €
BSPT-10	10	41	0,04	✓	1,50 €
BSPT-12	12	42	0,04	✓	1,50 €
BSPT-14	14	42	0,04	✓	1,50 €

*Depending on availability - Dimensions in mm

Our other products



STRIP1000
Sealing brush strip,
1m length



UGH40
H Type Guide units,
For Ø40 actuators



RHTplss
High Temperature
Castor, up to 200kg



DGS1
Female rod ends,
Steel / steel -
Economy range



SVG
Adjustable latch
clamp with strike
plate, Stroke from
82mm to 92mm



GCH
Linear ball slide -
Stainless steel balls,
Chariot - from 514 N
to 1...



PHTss
Pull handle, Up to 250
°C




SH2
Parallel axis helical
gear, Machined plastic
(delrin)



RTTss
Locking assembly,
Medium/high torque



 BLH20
Right angled gearbox,
from 0.53 to 1.77



B
Steel bevel gear, 1:1



E30
Right angle helical
reducers, from 1.50 to
9 Nm

Complementary products



GMC_GMK_BR
Guiding profile clamp,
Flat or rounded



APB_F
Adjusting rod for
clamp - Male,
Threaded



SDG
Adjustable guide
support bracket,
Plastic



SDG_SS
Universal adjustable
guide support
bracket, Stainless
steel