

End cap for square tube

Stock Pla



BTC

Black plastic

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details

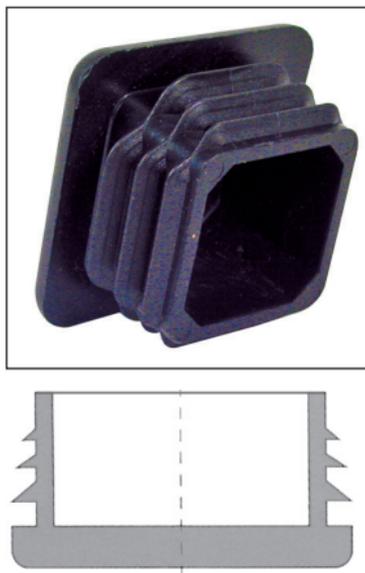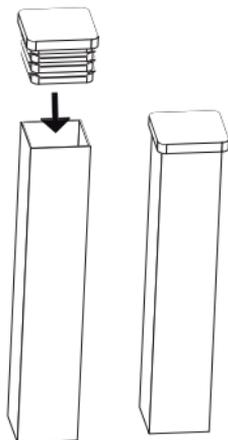

DISCOUNTS

Qty	1+	60+	100+	200+
Disc. List		-5%	-10%	On request

Part number	External tube	Tube thickness	Stock*	Price each 1 to 59
BTC10	10x10	1-2	-	0,17 €
BTC12	12x12	1-2	-	0,17 €
BTC13	13x13	0,5-2	-	0,22 €
BTC15	15x15	1-2	✓	0,22 €
BTC16	16x16	1-2,5	✓	0,24 €
BTC18	18x18	1,5-3	-	0,24 €
BTC20	20x20	1-3	✓	0,24 €
BTC22	22x22	1-3	-	0,27 €
BTC25/1-3	25x25	1-3	✓	0,27 €
BTC28	28x28	1-3	-	0,57 €
BTC30/1-2,5	30x30	1-3	✓	0,57 €
BTC30/2,5-4,5	30x30	2,5-4,5	✓	0,70 €
BTC35/1-3	35x35	1-3	✓	1,05 €
BTC35/2,5-5	35x35	2,5-5	✓	1,05 €
BTC40/1-3	40x40	1-3	✓	1,40 €
BTC40/2,5-4	40x40	3-5	-	1,40 €

Part number	External tube	Tube thickness	Stock*	Price each 1 to 59
BTC40/5-5,5	40x40	4,5-5,5	✓	1,40 €
BTC45	45x45	1-3	✓	1,53 €
BTC50/1-2,5	50x50	1-2,5	✓	1,78 €
BTC50/2,6-4	50x50	2,6-4	✓	1,94 €
BTC50/3,5-6	50x50	3,5-6	✓	2,01 €
BTC60/1,5-3,5	60x60	1-3,5	✓	3,13 €
BTC60/3-5	60x60	3-5	✓	3,13 €
BTC70	70x70	2-5	✓	5,26 €
BTC80/2-4	80x80	2-4	✓	5,87 €
BTC80/3-5	80x80	2,5-5	-	6,14 €
BTC90/2-5	90x90	2-5	-	10,52 €
BTC100/1-4	100x100	1-4	✓	11,94 €
BTC100/5-8	100x100	5-8	✓	11,88 €
BTC120	120x120	2,5-6	✓	18,44 €
BTC150/5-8	150x150	5-8	-	31,23 €
BTC150/10-12,5	150x150	10-12,5	-	31,23 €

*Depending on availability - Dimensions in mm

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details.



DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Ext. Ø of tube	Tube thickness		Price each 1 to 59
BTC20-10	20x10	1-2	-	0,22 €
BTC20-15	20x15	1-2	-	0,27 €
BTC25-10	25x10	1-2	-	0,34 €
BTC25-15	25x15	1-2,5	-	0,34 €
BTC25-20	25x20	1-3	-	0,34 €
BTC30-10	30x10	1-2	-	0,45 €
BTC30-15	30x15	1-3	✓	0,45 €
BTC30-20	30x20	1-3	✓	0,49 €
BTC30-25	30x25	1-3	-	On request
BTC35-10	35x10	1-2	-	On request
BTC35-20	35x20	1-3	✓	0,64 €
BTC35-25	35x25	1-3	-	On request
BTC35-30	35x30	1-1,5	-	1,40 €
BTC40-10	40x10	1,5-2	-	On request
BTC40-15	40x15	1-2	-	0,64 €
BTC40-20/1-3	40x20	1-3	-	0,85 €
BTC40-25	40x25	1-3	-	0,92 €
BTC40-30	40x30	1-3	-	0,98 €
BTC40-35	40x35	1-3	-	On request
BTC45-15	45x15	1-2	-	On request
BTC45-20	45x20	1-3	-	On request
BTC45-25	45x25	1,5-3	-	On request
BTC45-30	45x30	1-2,5	-	On request
BTC45-35	45x35	1-3,5	-	On request
BTC50-10	50x10	1-2	-	0,98 €
BTC50-20	50x20	1-3	-	1,05 €
BTC50-25	50x25	1-3	✓	1,11 €
BTC50-30/1,5-3	50x30	1,5-3	✓	1,11 €
BTC50-30/3-5	50x30	3-5	-	1,45 €
BTC50-35	50x35	1-3,5	-	On request
BTC50-40	50x40	1-3	-	1,53 €
BTC55-34	55x34	1,5-4	-	On request

Part number	Ext. Ø of tube	Tube thickness		Price each 1 to 59
BTC55-40	55x40	1,5-4	-	On request
BTC60-15	60x15	1-2	-	1,40 €
BTC60-20	60x20	1-3	-	1,45 €
BTC60-25	60x25	1-3	-	1,59 €
BTC60-30	60x30	1-3	✓	1,67 €
BTC60-35	60x35	1,5-3,5	-	On request
BTC60-40/1-3	60x40	1-3	✓	2,19 €
BTC60-40/3-5	60x40	3-5	✓	4,29 €
BTC60-50	60x50	1,5-3,5	-	3,00 €
BTC70-20	70x20	1-3,5	-	On request
BTC70-25	70x25	1-2,5	-	On request
BTC70-30	70x30	1-3	-	2,66 €
BTC70-40/1-3	70x40	1-3	-	3,13 €
BTC80-20	80x20	1-3	-	2,59 €
BTC80-30/1-2,5	80x30	1-2,5	-	2,66 €
BTC80-30/2,5-4	80x30	2,5-4	-	2,74 €
BTC80-40/1-3	80x40	1-3	✓	2,88 €
BTC80-40/3,2-5	80x40	3,2-5	-	6,53 €
BTC80-50	80x50	1,5-4	✓	6,14 €
BTC80-60/1,5-3,5	80x60	1,5-3,5	-	6,45 €
BTC80-60/3,5-5	80x60	3,5-5	-	9,05 €
BTC100-40	100x40	1,5-4	✓	7,63 €
BTC100-50/2-3	100x50	2-3	✓	7,89 €
BTC100-50/1,5-4,5	100x50	1,5-4,5	-	8,23 €
BTC120-30	120x30	1-2,5	-	8,23 €
BTC120-40/2	120x40	2	-	15,33 €
BTC120-40/3-5	120x40	3-5	-	8,75 €
BTC120-60	120x60	1,5-5	✓	9,38 €
BTC120-80/2,5	120x80	2,5	-	12,89 €
BTC120-80/5-8	120x80	5-8	✓	12,89 €
BTC140-80	140x80	2-4,5	-	16,51 €
BTC150-100	150x100	3-8	-	20,06 €

* Depending on availability - Dimensions in mm

End cap for square tube, with threaded insert **Pla**


BTCM

Black plastic

- Materials:

End cap: fiberglass reinforced Polyamide
Threaded insert: nickel plated brass

Added to range

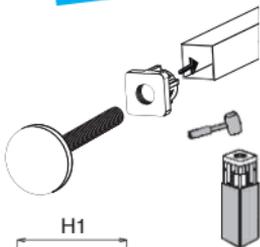


Option

- Stainless steel insert

Info.

- The values given are for static loads. For vibrating or moving loads, these values should be reduced

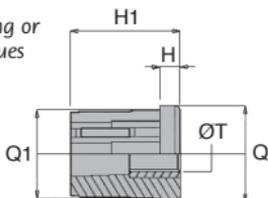

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each 1 to 59
BTC30/1.5-M8	M8	30	27,5	6	33	5000	30x1,5x27	-	10,25 €
BTC30/1.5-M10	M10	30	27,5	6	33	5000	30x1,5x27	✓	10,25 €
BTC30/1.5-M12	M12	30	27,5	6	33	5000	30x1,5x27	✓	10,25 €
BTC30/1.5-M14	M14	30	27,5	6	33	5000	30x1,5x27	-	10,25 €
BTC30/1.5-M16	M16	30	27,5	6	33	5000	30x1,5x27	-	10,25 €
BTC30/2-M8	M8	30	26,5	6	33	5000	30x2x26	✓	10,25 €
BTC30/2-M10	M10	30	26,5	6	33	5000	30x2x26	✓	10,25 €
BTC30/2-M12	M12	30	26,5	6	33	5000	30x2x26	-	10,25 €
BTC30/2-M14	M14	30	26,5	6	33	5000	30x2x26	-	10,25 €
BTC30/2-M16	M16	30	26,5	6	33	5000	30x2x26	-	10,25 €
BTC35/1.5-M10	M10	35	32,5	8	43	8000	35x1,5x32	-	11,01 €
BTC35/1.5-M12	M12	35	32,5	8	43	8000	35x1,5x32	✓	11,01 €
BTC35/1.5-M14	M14	35	32,5	8	43	8000	35x1,5x32	-	11,01 €
BTC35/1.5-M16	M16	35	32,5	8	43	8000	35x1,5x32	✓	11,01 €
BTC35/1.5-M20	M20	35	32,5	8	43	8000	35x1,5x32	-	11,01 €
BTC40/1.5-M8	M8	40	37,5	8	43	8000	40x1,5x37	-	11,53 €
BTC40/1.5-M10	M10	40	37,5	8	43	8000	40x1,5x37	✓	11,53 €
BTC40/1.5-M12	M12	40	37,5	8	43	8000	40x1,5x37	✓	11,53 €
BTC40/1.5-M14	M14	40	37,5	8	43	8000	40x1,5x37	-	11,48 €
BTC40/1.5-M16	M16	40	37,5	8	43	8000	40x1,5x37	✓	11,48 €
BTC40/1.5-M20	M20	40	37,5	8	43	8000	40x1,5x37	-	11,48 €
BTC40/2-M8	M8	40	36,5	8	43	10000	40x2x36	-	11,53 €
BTC40/2-M10	M10	40	36,5	8	43	10000	40x2x36	✓	11,48 €
BTC40/2-M12	M12	40	36,5	8	43	10000	40x2x36	✓	11,48 €
BTC40/2-M14	M14	40	36,5	8	43	10000	40x2x36	-	On request
BTC40/2-M16	M16	40	36,5	8	43	10000	40x2x36	✓	11,48 €
BTC40/2-M20	M20	40	36,5	8	43	10000	40x2x36	✓	11,48 €
BTC40/2,5-M8	M8	40	35,5	8	43	10000	40x2,5x35	-	11,53 €

*Depending on availability - Dimensions in mm

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each 1 to 59
BTC40/2.5-M10	M10	40	35,5	8	43	10000	40x2,5x35	-	11,53 €
BTC40/2.5-M12	M12	40	35,5	8	43	10000	40x2,5x35	✓	11,53 €
BTC40/2.5-M14	M14	40	35,5	8	43	10000	40x2,5x35	-	11,53 €
BTC40/2.5-M16	M16	40	35,5	8	43	10000	40x2,5x35	✓	11,53 €
BTC40/2.5-M20	M20	40	35,5	8	43	10000	40x2,5x35	-	11,53 €
BTC40/3-M8	M8	40	34,5	8	43	10000	40x3x34	-	11,53 €
BTC40/3-M10	M10	40	34,5	8	43	10000	40x3x34	-	11,53 €
BTC40/3-M12	M12	40	34,5	8	43	10000	40x3x34	-	11,53 €
BTC40/3-M14	M14	40	34,5	8	43	10000	40x3x34	-	11,53 €
BTC40/3-M16	M16	40	34,5	8	43	10000	40x3x34	-	11,53 €
BTC40/3-M20	M20	40	34,5	8	43	10000	40x3x34	-	11,53 €
BTC40/4-M8	M8	40	32,5	8	43	10000	40x4x32	-	11,53 €
BTC40/4-M10	M10	40	32,5	8	43	10000	40x4x32	-	11,53 €
BTC40/4-M12	M12	40	32,5	8	43	10000	40x4x32	-	11,53 €
BTC40/4-M14	M14	40	32,5	8	43	10000	40x4x32	-	11,53 €
BTC40/4-M16	M16	40	32,5	8	43	10000	40x4x32	-	11,53 €
BTC40/4-M20	M20	40	32,5	8	43	10000	40x4x32	-	11,53 €
BTC50/1.5-M10	M10	50	47,5	11	55	8000	50x1,5x47	-	13,75 €
BTC50/1.5-M12	M12	50	47,5	11	55	8000	50x1,5x47	✓	11,48 €
BTC50/1.5-M14	M14	50	47,5	11	55	8000	50x1,5x47	-	On request
BTC50/1.5-M16	M16	50	47,5	11	55	8000	50x1,5x47	-	11,48 €
BTC50/1.5-M20	M20	50	47,5	11	55	8000	50x1,5x47	-	11,48 €
BTC50/2-M8	M8	50	46,5	11	55	12000	50x2x46	-	13,75 €
BTC50/2-M10	M10	50	46,5	11	55	12000	50x2x46	✓	13,75 €
BTC50/2-M12	M12	50	46,5	11	55	12000	50x2x46	✓	13,75 €
BTC50/2-M14	M14	50	46,5	11	55	12000	50x2x46	-	13,75 €
BTC50/2-M16	M16	50	46,5	11	55	12000	50x2x46	✓	13,75 €
BTC50/2-M20	M20	50	46,5	11	55	12000	50x2x46	-	13,75 €
BTC50/2.5-M10	M10	50	45,5	11	55	12000	50x2,5x45	-	13,75 €
BTC50/2.5-M12	M12	50	45,5	11	55	12000	50x2,5x45	✓	11,48 €
BTC50/2.5-M14	M14	50	45,5	11	55	12000	50x2,5x45	-	On request
BTC50/2.5-M16	M16	50	45,5	11	55	12000	50x2,5x45	✓	11,48 €
BTC50/2.5-M20	M20	50	45,5	11	55	12000	50x2,5x45	-	11,48 €
BTC50/3-M10	M10	50	44,5	11	55	12000	50x3x44	-	13,75 €
BTC50/3-M12	M12	50	44,5	11	55	12000	50x3x44	-	13,75 €
BTC50/3-M14	M14	50	44,5	11	55	12000	50x3x44	-	13,75 €
BTC50/3-M16	M16	50	44,5	11	55	12000	50x3x44	-	13,75 €
BTC50/3-M20	M20	50	44,5	11	55	12000	50x3x44	-	13,75 €
BTC50/4-M10	M10	50	42,5	11	55	12000	50x4x42	-	13,75 €
BTC50/4-M12	M12	50	42,5	11	55	12000	50x4x42	-	13,75 €
BTC50/4-M14	M14	50	42,5	11	55	12000	50x4x42	-	13,75 €
BTC50/4-M16	M16	50	42,5	11	55	12000	50x4x42	-	13,75 €
BTC50/4-M20	M20	50	42,5	11	55	12000	50x4x42	-	13,75 €
BTC60/2-M10	M10	60	56,5	10	55	12000	60x2x56	-	14,67 €
BTC60/2-M12	M12	60	56,5	10	55	12000	60x2x56	-	14,67 €
BTC60/2-M14	M14	60	56,5	10	55	12000	60x2x56	-	14,67 €
BTC60/2-M16	M16	60	56,5	10	55	12000	60x2x56	-	14,67 €
BTC60/2-M20	M20	60	56,5	10	55	12000	60x2x56	-	14,67 €
BTC60/3-M10	M10	60	54,5	10	55	12000	60x3x54	-	14,67 €
BTC60/3-M12	M12	60	54,5	10	55	12000	60x3x54	-	14,67 €
BTC60/3-M14	M14	60	54,5	10	55	12000	60x3x54	-	14,67 €
BTC60/3-M16	M16	60	54,5	10	55	12000	60x3x54	-	14,67 €
BTC60/3-M20	M20	60	54,5	10	55	12000	60x3x54	-	14,67 €
BTC60/4-M10	M10	60	52,5	10	55	12000	60x4x52	-	14,67 €
BTC60/4-M12	M12	60	52,5	10	55	12000	60x4x52	✓	14,67 €
BTC60/4-M14	M14	60	52,5	10	55	12000	60x4x52	-	14,67 €
BTC60/4-M16	M16	60	52,5	10	55	12000	60x4x52	-	14,67 €
BTC60/4-M20	M20	60	52,5	10	55	12000	60x4x52	-	14,67 €

*Depending on availability - Dimensions in mm