

End cap for square tube

Stock Pla



BTC

Black plastic

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details

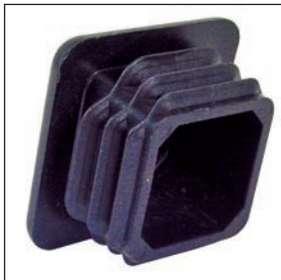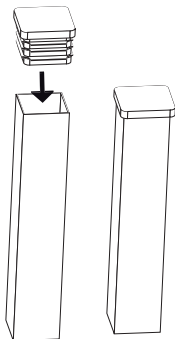

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	External Ø of tube	Tube thickness	Stock*	Price each 1 to 59
BTC10	10x10	1,5-2	-	0,16 €
BTC12	12x12	1,5-2	-	0,16 €
BTC13	13x13	1,5-2	-	On request
BTC15	15x15	1,5-2	✓	0,20 €
BTC16	16x16	1,5-2	✓	0,20 €
BTC18	18x18	1,5-3	-	0,20 €
BTC20	20x20	1-3	✓	0,20 €
BTC22	22x22	1-3	-	0,25 €
BTC25/1-3	25x25	1-3	✓	0,25 €
BTC28	28x28	1,5-3	-	0,48 €
BTC30/1-2,5	30x30	1-2,5	✓	0,48 €
BTC30/2,5-4,5	30x30	2,5-4,5	✓	0,59 €
BTC35/1-3	35x35	1-3	✓	0,89 €
BTC35/2,5-5	35x35	2,5-5	✓	0,89 €
BTC40/1-3	40x40	1-3	✓	1,18 €
BTC40/2,5-4	40x40	2,5-4	✓	1,18 €
BTC40/5-5,5	40x40	5-5,5	-	1,18 €

Part number	External Ø of tube	Tube thickness	Stock*	Price each 1 to 59
BTC40/4-4,5	40x40	4-4,5	-	1,18 €
BTC45	45x45	1-3	✓	1,29 €
BTC50/1-2,5	50x50	1-2,5	✓	1,49 €
BTC50/2,6-4	50x50	2,6-4	✓	1,63 €
BTC50/3,5-6	50x50	3,5-6	✓	1,68 €
BTC60/1,5-3,5	60x60	1,5-3,5	✓	2,62 €
BTC60/3-5	60x60	3-5	✓	2,62 €
BTC70	70x70	2-4	✓	4,38 €
BTC80/2-4	80x80	2-4	✓	4,89 €
BTC80/3-5	80x80	3-5	✓	5,11 €
BTC90/2-5	90x90	2-5	-	8,75 €
BTC90/3,6-5	90x90	3,6-5	-	8,65 €
BTC100/1-4	100x100	1-4	✓	9,92 €
BTC100/5-8	100x100	5-8	✓	9,88 €
BTC120	120x120	2,5-5	✓	15,31 €
BTC150/5-8	150x150	5-8	-	25,93 €
BTC150/10-12,5	150x150	10-12,5	-	25,93 €

*Depending on availability - Dimensions in mm

Our other products



HLC19

Right angle spiro bevel gearbox, Up to 43Nm



PTA80ssEB

Articulated foot with sheet metal base Ø80, Articulated foot



CFS

Miniature cam follower, Miniature



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



INS100

Self tapping inserts-coarse thread, Coarse thread



MSP3815

Masterplate® glueable insert rectangular, rectangular with nut



TBD

Manual leadscrew table with opposing threads, 20kg



CMAss

Eye bolt stainless steel, Stainless steel



PSG35

Spur gear - precision Range 882, Stainless steel



BHC

Socket head button screw, Stainless steel



BCAss

Stainless steel splined bush, Inox



PT882

Drive sprocket for slat top chain, Range 882

Complementary products



BTC_M

End cap with threaded insert for square tube, With threaded insert



TUBE25_25

Square Tube, Aluminium or Stainless steel