

End cap for square tube, with threaded insert **Pla**

BTCM

Black plastic

Added to range

- Materials:



End cap: fiberglass reinforced Polyamide
Threaded insert: nickel plated brass

Option

- Stainless steel insert

Info.

- For static application only

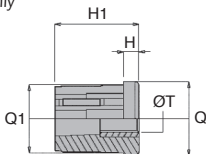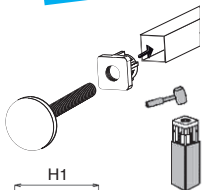

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each
BTC30/1.5-M8	M8	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M10	M10	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M12	M12	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M14	M14	30	27,5	6	33	5000	30x1,5x27	-	8,60 €
BTC30/1.5-M16	M16	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/2-M8	M8	30	26,5	6	33	5000	30x2x26	✓	8,60 €
BTC30/2-M10	M10	30	26,5	6	33	5000	30x2x26	✓	8,60 €
BTC30/2-M12	M12	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC30/2-M14	M14	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC30/2-M16	M16	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC35/1.5-M10	M10	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC35/1.5-M12	M12	35	32,5	8	43	8000	35x1,5x32	✓	9,24 €
BTC35/1.5-M14	M14	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC35/1.5-M16	M16	35	32,5	8	43	8000	35x1,5x32	✓	9,24 €
BTC35/1.5-M20	M20	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC40/1.5-M8	M8	40	37,5	8	43	8000	40x1,5x37	-	9,68 €
BTC40/1.5-M10	M10	40	37,5	8	43	8000	40x1,5x37	✓	9,68 €
BTC40/1.5-M12	M12	40	37,5	8	43	8000	40x1,5x37	✓	9,68 €
BTC40/1.5-M14	M14	40	37,5	8	43	8000	40x1,5x37	-	9,64 €
BTC40/1.5-M16	M16	40	37,5	8	43	8000	40x1,5x37	✓	9,64 €
BTC40/1.5-M20	M20	40	37,5	8	43	8000	40x1,5x37	-	9,64 €
BTC40/2-M8	M8	40	36,5	8	43	10000	40x2x36	-	9,68 €
BTC40/2-M10	M10	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M12	M12	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M14	M14	40	36,5	8	43	10000	40x2x36	-	9,64 €
BTC40/2-M16	M16	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M20	M20	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2,5-M8	M8	40	35,5	8	43	10000	40x2,5x35	-	9,68 €

*Depending on availability - Dimensions in mm

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock ¹	Price each 1 to 19
BTC40/2.5-M10	M10	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M12	M12	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M14	M14	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M16	M16	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M20	M20	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/3-M8	M8	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M10	M10	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M12	M12	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M14	M14	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M16	M16	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M20	M20	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/4-M8	M8	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M10	M10	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M12	M12	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M14	M14	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M16	M16	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M20	M20	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC50/1.5-M10	M10	50	47,5	11	55	8000	50x1,5x47	-	11,53 €
BTC50/1.5-M12	M12	50	47,5	11	55	8000	50x1,5x47	✓	9,64 €
BTC50/1.5-M14	M14	50	47,5	11	55	8000	50x1,5x47	-	9,64 €
BTC50/1.5-M16	M16	50	47,5	11	55	8000	50x1,5x47	✓	9,64 €
BTC50/1.5-M20	M20	50	47,5	11	55	8000	50x1,5x47	-	9,64 €
BTC50/2-M8	M8	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2-M10	M10	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M12	M12	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M14	M14	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2-M16	M16	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M20	M20	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2.5-M10	M10	50	45,5	11	55	12000	50x2,5x45	-	11,53 €
BTC50/2.5-M12	M12	50	45,5	11	55	12000	50x2,5x45	✓	9,64 €
BTC50/2.5-M14	M14	50	45,5	11	55	12000	50x2,5x45	-	9,64 €
BTC50/2.5-M16	M16	50	45,5	11	55	12000	50x2,5x45	✓	9,64 €
BTC50/2.5-M20	M20	50	45,5	11	55	12000	50x2,5x45	-	9,64 €
BTC50/3-M10	M10	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M12	M12	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M14	M14	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M16	M16	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M20	M20	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/4-M10	M10	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M12	M12	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M14	M14	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M16	M16	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M20	M20	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC60/2-M10	M10	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M12	M12	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M14	M14	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M16	M16	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M20	M20	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/3-M10	M10	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M12	M12	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M14	M14	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M16	M16	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M20	M20	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/4-M10	M10	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M12	M12	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M14	M14	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M16	M16	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M20	M20	60	52,5	10	55	12000	60x4x52	-	12,32 €

¹Depending on availability - Dimensions in mm

Our other products



BWU

Compact precision slide, from 1510 N to 10500 N



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis



PO

Pull handle - Multi-sector, Tapped recessed insert



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...




PSG05S

Spur gear - precision range, Stainless steel 303



CHAE3030PA

 Square decorative screwed hinges, Polyamide



RPP8

RPP heavy duty timing belt, RPP8



SCE_SS

Stainless steel U-shaped clamp, Stainless steel



IN1

Internal gear, Steel 20NCD2



RBNtc

Swivel castor with central hole, Steel -



CHT

Asynchronous AC Motor 1.1 to 1.85kW,



PGM52-M4

Pull handle, Aluminium

Complementary products



BTC

End cap for square tube, Standard



BPTR_M

End cap with threaded insert for round tube, With threaded insert