

End cap for square tube, with threaded insert **Pla**

BTCM

Black plastic

Added to range

- Materials:



End cap: fiberglass reinforced Polyamide
Threaded insert: nickel plated brass

Option

- Stainless steel insert

Info.

- For static application only

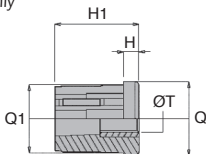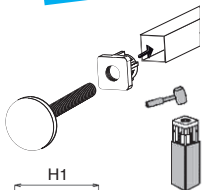

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each
BTC30/1.5-M8	M8	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M10	M10	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M12	M12	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M14	M14	30	27,5	6	33	5000	30x1,5x27	-	8,60 €
BTC30/1.5-M16	M16	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/2-M8	M8	30	26,5	6	33	5000	30x2x26	✓	8,60 €
BTC30/2-M10	M10	30	26,5	6	33	5000	30x2x26	✓	8,60 €
BTC30/2-M12	M12	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC30/2-M14	M14	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC30/2-M16	M16	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC35/1.5-M10	M10	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC35/1.5-M12	M12	35	32,5	8	43	8000	35x1,5x32	✓	9,24 €
BTC35/1.5-M14	M14	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC35/1.5-M16	M16	35	32,5	8	43	8000	35x1,5x32	✓	9,24 €
BTC35/1.5-M20	M20	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC40/1.5-M8	M8	40	37,5	8	43	8000	40x1,5x37	-	9,68 €
BTC40/1.5-M10	M10	40	37,5	8	43	8000	40x1,5x37	✓	9,68 €
BTC40/1.5-M12	M12	40	37,5	8	43	8000	40x1,5x37	✓	9,68 €
BTC40/1.5-M14	M14	40	37,5	8	43	8000	40x1,5x37	-	9,64 €
BTC40/1.5-M16	M16	40	37,5	8	43	8000	40x1,5x37	✓	9,64 €
BTC40/1.5-M20	M20	40	37,5	8	43	8000	40x1,5x37	-	9,64 €
BTC40/2-M8	M8	40	36,5	8	43	10000	40x2x36	-	9,68 €
BTC40/2-M10	M10	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M12	M12	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M14	M14	40	36,5	8	43	10000	40x2x36	-	9,64 €
BTC40/2-M16	M16	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M20	M20	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2,5-M8	M8	40	35,5	8	43	10000	40x2,5x35	-	9,68 €

*Depending on availability - Dimensions in mm

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock ¹	Price each 1 to 19
BTC40/2.5-M10	M10	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M12	M12	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M14	M14	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M16	M16	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M20	M20	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/3-M8	M8	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M10	M10	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M12	M12	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M14	M14	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M16	M16	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M20	M20	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/4-M8	M8	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M10	M10	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M12	M12	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M14	M14	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M16	M16	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M20	M20	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC50/1.5-M10	M10	50	47,5	11	55	8000	50x1,5x47	-	11,53 €
BTC50/1.5-M12	M12	50	47,5	11	55	8000	50x1,5x47	✓	9,64 €
BTC50/1.5-M14	M14	50	47,5	11	55	8000	50x1,5x47	-	9,64 €
BTC50/1.5-M16	M16	50	47,5	11	55	8000	50x1,5x47	✓	9,64 €
BTC50/1.5-M20	M20	50	47,5	11	55	8000	50x1,5x47	-	9,64 €
BTC50/2-M8	M8	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2-M10	M10	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M12	M12	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M14	M14	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2-M16	M16	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M20	M20	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2.5-M10	M10	50	45,5	11	55	12000	50x2,5x45	-	11,53 €
BTC50/2.5-M12	M12	50	45,5	11	55	12000	50x2,5x45	✓	9,64 €
BTC50/2.5-M14	M14	50	45,5	11	55	12000	50x2,5x45	-	9,64 €
BTC50/2.5-M16	M16	50	45,5	11	55	12000	50x2,5x45	✓	9,64 €
BTC50/2.5-M20	M20	50	45,5	11	55	12000	50x2,5x45	-	9,64 €
BTC50/3-M10	M10	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M12	M12	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M14	M14	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M16	M16	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M20	M20	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/4-M10	M10	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M12	M12	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M14	M14	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M16	M16	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M20	M20	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC60/2-M10	M10	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M12	M12	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M14	M14	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M16	M16	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M20	M20	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/3-M10	M10	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M12	M12	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M14	M14	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M16	M16	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M20	M20	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/4-M10	M10	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M12	M12	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M14	M14	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M16	M16	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M20	M20	60	52,5	10	55	12000	60x4x52	-	12,32 €

¹Depending on availability - Dimensions in mm

Our other products



CHN_CHN55

Straight long link stainless steel chain, Stainless steel



GEC

Rubber latch clamp with strike plate, Lockable



CHMBR

Reaction arm, CHM and CHMR gear reducers reaction arm



AT5P_AT10P

Connecting plate for AT type timing belts, AT10



AC

Strike for toggle latch, 15mm



BH01

Single housed bearing, Bearing fitted with adhesive



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



PRF_BV

Screw block, Panel addition and fastening



FF50

Offset spur gear reducer, from 111 to 425 Nm



ACLBDB

Closing mechanism for aluminium profile, Dual ball catch



ACLBMC

Detector support for aluminium profile, Sensor holder



BOXsap

Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752

Complementary products



BTC

End cap for square tube, Standard



BPTR_M

End cap with threaded insert for round tube, With threaded insert