

End cap for square tube, with threaded insert **Pla**

BTCM

Black plastic

Added to range

- Materials:



End cap: fibreglass reinforced Polyamide
Threaded insert: nickel plated brass

Option

- Stainless steel insert

Info.

- For static application only

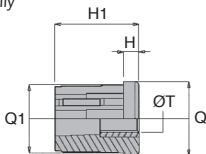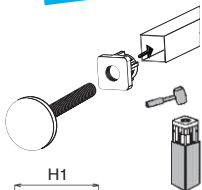

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request


Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock*	Price each
BTC30/1.5-M8	M8	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M10	M10	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M12	M12	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/1.5-M14	M14	30	27,5	6	33	5000	30x1,5x27	-	8,60 €
BTC30/1.5-M16	M16	30	27,5	6	33	5000	30x1,5x27	✓	8,60 €
BTC30/2-M8	M8	30	26,5	6	33	5000	30x2x26	✓	8,60 €
BTC30/2-M10	M10	30	26,5	6	33	5000	30x2x26	✓	8,60 €
BTC30/2-M12	M12	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC30/2-M14	M14	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC30/2-M16	M16	30	26,5	6	33	5000	30x2x26	-	8,60 €
BTC35/1.5-M10	M10	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC35/1.5-M12	M12	35	32,5	8	43	8000	35x1,5x32	✓	9,24 €
BTC35/1.5-M14	M14	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC35/1.5-M16	M16	35	32,5	8	43	8000	35x1,5x32	✓	9,24 €
BTC35/1.5-M20	M20	35	32,5	8	43	8000	35x1,5x32	-	9,24 €
BTC40/1.5-M8	M8	40	37,5	8	43	8000	40x1,5x37	-	9,68 €
BTC40/1.5-M10	M10	40	37,5	8	43	8000	40x1,5x37	✓	9,68 €
BTC40/1.5-M12	M12	40	37,5	8	43	8000	40x1,5x37	✓	9,68 €
BTC40/1.5-M14	M14	40	37,5	8	43	8000	40x1,5x37	-	9,64 €
BTC40/1.5-M16	M16	40	37,5	8	43	8000	40x1,5x37	✓	9,64 €
BTC40/1.5-M20	M20	40	37,5	8	43	8000	40x1,5x37	-	9,64 €
BTC40/2-M8	M8	40	36,5	8	43	10000	40x2x36	-	9,68 €
BTC40/2-M10	M10	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M12	M12	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M14	M14	40	36,5	8	43	10000	40x2x36	-	9,64 €
BTC40/2-M16	M16	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2-M20	M20	40	36,5	8	43	10000	40x2x36	✓	9,64 €
BTC40/2,5-M8	M8	40	35,5	8	43	10000	40x2,5x35	-	9,68 €

*Depending on availability - Dimensions in mm

Part number	ØT	Q	Q1	H	H1	Static load (N)	Tube dimensions	Stock ¹	Price each 1 to 19
BTC40/2.5-M10	M10	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M12	M12	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M14	M14	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M16	M16	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/2.5-M20	M20	40	35,5	8	43	10000	40x2,5x35	-	9,68 €
BTC40/3-M8	M8	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M10	M10	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M12	M12	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M14	M14	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M16	M16	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/3-M20	M20	40	34,5	8	43	10000	40x3x34	-	9,68 €
BTC40/4-M8	M8	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M10	M10	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M12	M12	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M14	M14	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M16	M16	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC40/4-M20	M20	40	32,5	8	43	10000	40x4x32	-	9,68 €
BTC50/1.5-M10	M10	50	47,5	11	55	8000	50x1,5x47	-	11,53 €
BTC50/1.5-M12	M12	50	47,5	11	55	8000	50x1,5x47	✓	9,64 €
BTC50/1.5-M14	M14	50	47,5	11	55	8000	50x1,5x47	-	9,64 €
BTC50/1.5-M16	M16	50	47,5	11	55	8000	50x1,5x47	✓	9,64 €
BTC50/1.5-M20	M20	50	47,5	11	55	8000	50x1,5x47	-	9,64 €
BTC50/2-M8	M8	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2-M10	M10	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M12	M12	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M14	M14	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2-M16	M16	50	46,5	11	55	12000	50x2x46	✓	11,53 €
BTC50/2-M20	M20	50	46,5	11	55	12000	50x2x46	-	11,53 €
BTC50/2.5-M10	M10	50	45,5	11	55	12000	50x2,5x45	-	11,53 €
BTC50/2.5-M12	M12	50	45,5	11	55	12000	50x2,5x45	✓	9,64 €
BTC50/2.5-M14	M14	50	45,5	11	55	12000	50x2,5x45	-	9,64 €
BTC50/2.5-M16	M16	50	45,5	11	55	12000	50x2,5x45	✓	9,64 €
BTC50/2.5-M20	M20	50	45,5	11	55	12000	50x2,5x45	-	9,64 €
BTC50/3-M10	M10	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M12	M12	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M14	M14	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M16	M16	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/3-M20	M20	50	44,5	11	55	12000	50x3x44	-	11,53 €
BTC50/4-M10	M10	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M12	M12	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M14	M14	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M16	M16	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC50/4-M20	M20	50	42,5	11	55	12000	50x4x42	-	11,53 €
BTC60/2-M10	M10	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M12	M12	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M14	M14	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M16	M16	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/2-M20	M20	60	56,5	10	55	12000	60x2x56	-	12,32 €
BTC60/3-M10	M10	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M12	M12	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M14	M14	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M16	M16	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/3-M20	M20	60	54,5	10	55	12000	60x3x54	-	12,32 €
BTC60/4-M10	M10	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M12	M12	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M14	M14	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M16	M16	60	52,5	10	55	12000	60x4x52	-	12,32 €
BTC60/4-M20	M20	60	52,5	10	55	12000	60x4x52	-	12,32 €


¹Depending on availability - Dimensions in mm

Our other products

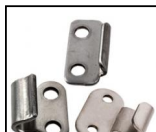

AC

 Strike for toggle latch,
12,13,18 and 20mm



TBV

Manual lifting tables,
3kg




CLSCLP_SS

Clevis components,
short version,
Stainless steel - short
range



BLM

Spring loaded plunger
with ball tip, Stainless
steel body

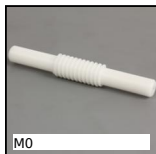


MO

Worm and wheel set,
Machined plastic
(delrin)



VDS

Sliding lock
adjustment system,
Sliding lock for oblong
hole

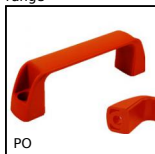


PO

Pull handle - Multi-
sector, Smooth hole



RDE-W

 Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



PF20

Worm and wheel gear
reducer, up to 5 Nm



PRF_ECL

Nut for aluminium
profile, Stainless steel



CHMR110

Worm and wheel gear
reducer, up to 980



RCX-6

Spherical tilt washer -
DIN6319, concave

Complementary products



BTC

End cap for square
tube, Standard



BPTR_M

End cap with threaded
insert for round tube,
With threaded insert