

End cap for rectangular tube

Stock Pla


BTC

Black plastic

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details.

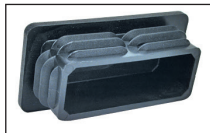

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Ext. Ø of tube	Tube thickness	Stock*	Price each 1 to 59
BTC20-10	20x10	1-2	-	0,20 €
BTC20-15	20x15	1-2	-	0,25 €
BTC25-10	25x10	1-2	-	0,31 €
BTC25-15	25x15	1-2,5	✓	0,31 €
BTC25-20	25x20	1-3	-	0,31 €
BTC30-10	30x10	1-2	-	0,41 €
BTC30-15	30x15	1-3	✓	0,41 €
BTC30-20	30x20	1-3	✓	0,45 €
BTC30-25	30x25	1-3	-	On request
BTC35-10	35x10	1-2	-	On request
BTC35-20	35x20	1-3	✓	0,57 €
BTC35-25	35x25	1-3	-	On request
BTC35-30	35x30	1-1,5	-	1,26 €
BTC40-10	40x10	1,5-2	-	On request
BTC40-15	40x15	1-2	-	0,57 €
BTC40-20/1-2	40x20	1-3	-	0,76 €
BTC40-25	40x25	1-3	-	0,82 €
BTC40-30	40x30	1-3	-	0,88 €
BTC40-35	40x35	1-3	-	On request
BTC45-15	45x15	1-2	-	On request
BTC45-20	45x20	1-3	-	On request
BTC45-25	45x25	1,5-3	-	On request
BTC45-30	45x30	1-2,5	-	On request
BTC45-35	45x35	1-3,5	-	On request
BTC50-10	50x10	1-2	-	0,88 €
BTC50-20	50x20	1-3	-	0,94 €
BTC50-25	50x25	1-3	✓	1,00 €
BTC50-30/1,5-2	50x30	1-3	-	On request
BTC50-30/3	50x30	3-5	-	On request
BTC50-35	50x35	1-3,5	-	On request
BTC50-40	50x40	1-3	-	1,37 €
BTC55-34	55x34	1,5-4	-	On request

Part number	Ext. Ø of tube	Tube thickness	Stock*	Price each 1 to 59
BTC55-40	55x40	1,5-4	-	On request
BTC60-15	60x15	1-2	-	1,26 €
BTC60-20	60x20	1-3	-	1,31 €
BTC60-25	60x25	1-3	-	1,43 €
BTC60-30	60x30	1-3	✓	1,50 €
BTC60-35	60x35	1,5-3,5	-	On request
BTC60-40/1-3	60x40	1-3	✓	1,97 €
BTC60-40/4-5	60x40	3-5	-	3,87 €
BTC60-50	60x50	1,5-3,5	-	2,70 €
BTC70-20	70x20	1-3,5	-	On request
BTC70-25	70x25	1-2,5	-	On request
BTC70-30	70x30	1-3	-	2,39 €
BTC70-40/1,5-2	70x40	1-3	-	2,81 €
BTC80-20	80x20	1-3	-	2,33 €
BTC80-30/1-2,5	80x30	1-2,5	-	2,39 €
BTC80-30/2,5-4	80x30	2,5-4	-	2,46 €
BTC80-40/1-3	80x40	1-3	✓	2,59 €
BTC80-40/3,2-4	80x40	3,2-5	-	On request
BTC80-50	80x50	1,5-4	✓	5,52 €
BTC80-60/2,5-3	80x60	1,5-3,5	-	5,81 €
BTC80-60/5	80x60	3,5-5	-	8,14 €
BTC100-40	100x40	1,5-4	✓	6,86 €
BTC100-50/2-3	100x50	2-3	✓	7,10 €
BTC100-50/3,2-5	100x50	1,5-4,5	-	On request
BTC120-30	120x30	1-2,5	-	7,40 €
BTC120-40/2	120x40	2	-	13,80 €
BTC120-40/3-5	120x40	3-5	-	7,87 €
BTC120-60	120x60	1,5-5	✓	8,44 €
BTC120-80/2-3	120x80	2-5	-	11,60 €
BTC120-80/5-8	120x80	5-8	✓	11,60 €
BTC140-80	140x80	2-4,5	-	14,86 €
BTC150-100	150x100	1,5-5	-	18,05 €

*Depending on availability - Dimensions in mm

Our other products



PSG35

Spur gear - precision range, Stainless steel 316



BAP

Plastic clamping collar, Ø10 - Ø20



HG5

Steel spur gear, Steel 20NCD2



M1

Worm and wheel set, Non hardened steel



M0

Worm and wheel set, Machined plastic (delrin)



 
CLLCLLP

Clevis components, long version, Steel - long range



TFR

Rigid manual tensioner, Fixed



TIFbout

Threaded stud - DIN976A, Steel



PTAF80-PAMF80

Articulated fixable foot with pressed



CCL

Standard wire thimble, Steel



SLB

Indexing plunger, steel class 5.8



AC

Strike for toggle latch, 12,13,18 and 20mm

Complementary products



BTC

End cap for square tube, Standard



BPTR

End cap for round tube, Standard