

End cap for rectangular tube

Stock Pla


BTC

Black plastic

- Material: black technopolymer

Info.

- Dimensions are given as a guide and are subject to change
- Not sold individually, please contact us for details.

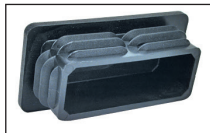

DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Ext. Ø of tube	Tube thickness	Stock*	Price each 1 to 59
BTC20-10	20x10	1-2	-	0,20 €
BTC20-15	20x15	1-2	-	0,25 €
BTC25-10	25x10	1-2	-	0,31 €
BTC25-15	25x15	1-2,5	✓	0,31 €
BTC25-20	25x20	1-3	-	0,31 €
BTC30-10	30x10	1-2	-	0,41 €
BTC30-15	30x15	1-3	✓	0,41 €
BTC30-20	30x20	1-3	✓	0,45 €
BTC30-25	30x25	1-3	-	On request
BTC35-10	35x10	1-2	-	On request
BTC35-20	35x20	1-3	✓	0,57 €
BTC35-25	35x25	1-3	-	On request
BTC35-30	35x30	1-1,5	-	1,26 €
BTC40-10	40x10	1,5-2	-	On request
BTC40-15	40x15	1-2	-	0,57 €
BTC40-20/1-2	40x20	1-3	-	0,76 €
BTC40-25	40x25	1-3	-	0,82 €
BTC40-30	40x30	1-3	-	0,88 €
BTC40-35	40x35	1-3	-	On request
BTC45-15	45x15	1-2	-	On request
BTC45-20	45x20	1-3	-	On request
BTC45-25	45x25	1,5-3	-	On request
BTC45-30	45x30	1-2,5	-	On request
BTC45-35	45x35	1-3,5	-	On request
BTC50-10	50x10	1-2	-	0,88 €
BTC50-20	50x20	1-3	-	0,94 €
BTC50-25	50x25	1-3	✓	1,00 €
BTC50-30/1,5-2	50x30	1-3	-	On request
BTC50-30/3	50x30	3-5	-	On request
BTC50-35	50x35	1-3,5	-	On request
BTC50-40	50x40	1-3	-	1,37 €
BTC55-34	55x34	1,5-4	-	On request

Part number	Ext. Ø of tube	Tube thickness	Stock*	Price each 1 to 59
BTC55-40	55x40	1,5-4	-	On request
BTC60-15	60x15	1-2	-	1,26 €
BTC60-20	60x20	1-3	-	1,31 €
BTC60-25	60x25	1-3	-	1,43 €
BTC60-30	60x30	1-3	✓	1,50 €
BTC60-35	60x35	1,5-3,5	-	On request
BTC60-40/1-3	60x40	1-3	✓	1,97 €
BTC60-40/4-5	60x40	3-5	-	3,87 €
BTC60-50	60x50	1,5-3,5	-	2,70 €
BTC70-20	70x20	1-3,5	-	On request
BTC70-25	70x25	1-2,5	-	On request
BTC70-30	70x30	1-3	-	2,39 €
BTC70-40/1,5-2	70x40	1-3	-	2,81 €
BTC80-20	80x20	1-3	-	2,33 €
BTC80-30/1-2,5	80x30	1-2,5	-	2,39 €
BTC80-30/2,5-4	80x30	2,5-4	-	2,46 €
BTC80-40/1-3	80x40	1-3	✓	2,59 €
BTC80-40/3,2-4	80x40	3,2-5	-	On request
BTC80-50	80x50	1,5-4	✓	5,52 €
BTC80-60/2,5-3	80x60	1,5-3,5	-	5,81 €
BTC80-60/5	80x60	3,5-5	-	8,14 €
BTC100-40	100x40	1,5-4	✓	6,86 €
BTC100-50/2-3	100x50	2-3	✓	7,10 €
BTC100-50/3,2-5	100x50	1,5-4,5	-	On request
BTC120-30	120x30	1-2,5	-	7,40 €
BTC120-40/2	120x40	2	-	13,80 €
BTC120-40/3-5	120x40	3-5	-	7,87 €
BTC120-60	120x60	1,5-5	✓	8,44 €
BTC120-80/2-3	120x80	2-5	-	11,60 €
BTC120-80/5-8	120x80	5-8	✓	11,60 €
BTC140-80	140x80	2-4,5	-	14,86 €
BTC150-100	150x100	1,5-5	-	18,05 €

*Depending on availability - Dimensions in mm

HPC WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



Clevis components, short version, Stainless steel - short range



Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



Die spring ISO10243, Heavy



Detectable plastic palm grip, blue thermoplastic



 
Chain sprocket - steel, 12.7mm (DIN08B-1)



Worm and wheel gear reducer, from 6.50 to 12.80 Nm



Base support plate for aluminium profile, Central base fixation



Door seal for aluminium profile, Black NBR



Adjustable cross clamp, Adjustable



Locking pin with interlocking safety



Articulated fixable foot with pressed



End support, With base

Complementary products



End cap for square tube, Standard



End cap for round tube, Standard