

Adjustable screw stop


Steel

BVR


- Allows to easily create a stop that is adjustable over a 50mm range
- Material:
Burnished treated steel

Application

- Can be adjusted over the full range
- Final position is locked using a counter-nut.

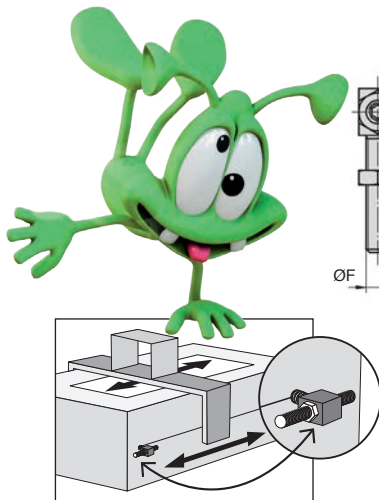

Travel stop

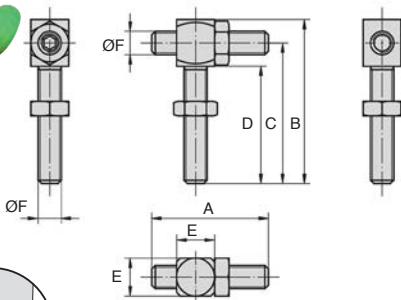

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	D	E	ØF	Price each 1 to 5
BVR6-30-30	30	44	37	30	10	M6	19,88 €
BVR8-40-40	40	56	48	40	13	M8	25,81 €
BVR10-50-50	50	70	60	50	17	M10	30,28 €
BVR12-60-60	60	84	72	60	19	M12	39,24 €
BVR16-80-80	80	112	96	80	24	M16	60,02 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

 
Fax

cial2@hpceurope.com

HPC SUPPLEMENT 2019

199

Our other products



RPP8

RPP heavy duty timing belt, RPP8



SDG_SS

Universal adjustable guide support bracket, Stainless steel



CHB

Worm and wheel gear reducer, up to 41 Nm



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80 with counter and handw...



RIMtce

Locking castor, with central hole



PSG25S

Spur gear - precision range, Stainless steel 303



G4

Steel spur gear, Steel 20NCD2



RVM25

Manually operated gearbox, Bevel



CLSCLP

Clevis components, short version, Steel -



GGP

Male wing knob, Technopolymer with



PX

Optional output shaft stainless steel, P



DOMI120

Accessories, Clamping lever

Complementary products