

Cylindrical elasto mount

Ste Stock

B-ZY

Male / female mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials
core: Steel plates
cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C


Uses

- Dampens sound and vibrations

Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

From
size M3
upwards

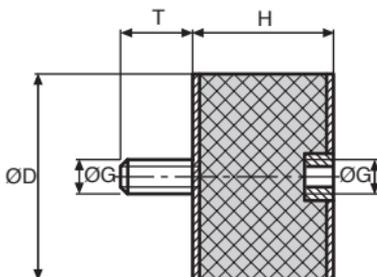

DISCOUNTS **A**

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS **B**

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shearing		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)	stiffness (N/mm)	Max. load (N)		
B-ZY3-8-8	M3	8	8	6	-	-	-	-	✓	A 4,03 €
B-ZY4-10-10	M4	10	10	10	48	43	10	35	✓	A 2,06 €
B-ZY4-10-15	M4	10	15	10	29	43	5	15	✓	A 2,19 €
B-ZY4-15-15	M4	15	15	10	67	95	15	35	✓	A 2,06 €
B-ZY4-15-20	M4	15	20	10	-	-	-	-	✓	A 2,16 €
B-ZY4-15-30	M4	15	30	15	-	-	-	-	✓	A 2,30 €
B-ZY5-15-15	M5	15	15	8	67	95	15	35	✓	A 2,16 €
B-ZY6-20-15	M6	20	15	18	130	170	24	60	✓	A 2,40 €
B-ZY6-20-20	M6	20	20	18	-	-	-	-	✓	A 2,39 €
B-ZY6-20-25	M6	20	25	18	61	170	11	60	✓	A 2,50 €
B-ZY6-25-15	M6	25	15	18	-	-	-	-	✓	A 2,73 €
B-ZY6-25-20	M6	25	20	18	130	280	30	95	✓	A 3,07 €
B-ZY6-25-25	M6	25	25	18	-	-	-	-	✓	A 3,17 €
B-ZY6-25-30	M6	25	30	18	71	280	19	95	✓	A 3,42 €
B-ZY8-30-15	M8	30	15	20	525	400	58	140	✓	A 3,75 €
B-ZY8-30-20	M8	30	20	20	235	400	42	140	✓	A 3,99 €
B-ZY8-30-25	M8	30	25	20	-	-	-	-	✓	A 4,33 €
B-ZY8-30-30	M8	30	30	20	113	400	28	140	✓	A 4,64 €
B-ZY8-30-40	M8	30	40	20	106	400	13	140	✓	A 5,21 €
B-ZY8-40-25	M8	40	25	23	-	-	-	-	✓	A 5,24 €
B-ZY8-40-30	M8	40	30	23	234	650	49	250	✓	A 5,89 €
B-ZY8-40-40	M8	40	40	23	147	650	23	250	✓	A 6,78 €
B-ZY10-40-30	M10	40	30	28	-	-	-	-	✓	A 6,34 €
B-ZY10-50-20	M10	50	20	28	857	1000	110	400	✓	A 7,68 €
B-ZY10-50-25	M10	50	25	28	-	-	-	-	✓	A 8,92 €
B-ZY10-50-30	M10	50	30	28	395	1000	73	400	✓	A 8,50 €
B-ZY10-50-40	M10	50	40	28	273	1000	58	400	✓	A 8,69 €
B-ZY10-50-45	M10	50	45	28	-	-	-	-	✓	A 8,90 €
B-ZY10-50-50	M10	50	50	28	210	1000	37	400	✓	A 9,51 €
B-ZY10-60-40	M10	60	40	28	-	-	-	-	✓	A 12,82 €
B-ZY10-70-45	M10	70	45	28	-	-	-	-	✓	A 19,25 €
B-ZY12-60-40	M12	60	40	33	-	-	-	-	✓	B 8,48 €
B-ZY12-75-25	M12	75	25	37	-	-	-	-	✓	B 0,00 €
B-ZY12-75-40	M12	75	40	37	735	2300	118	850	✓	B 0,25 €
B-ZY12-75-50	M12	75	50	37	530	2300	101	850	-	B 12,98 €
B-ZY12-75-55	M12	75	55	37	417	2300	78	850	-	B 13,52 €
B-ZY16-100-40	M16	100	40	41	2160	4200	283	1600	-	B 20,34 €
B-ZY16-100-55	M16	100	55	41	892	4200	145	1600	-	B 23,11 €
B-ZY16-100-60	M16	100	60	41	843	4200	142	1600	-	B 24,27 €
B-ZY16-100-75	M16	100	75	41	-	-	-	-	-	B 30,52 €

*Depending on availability - Dimensions in mm

Our other products



SLHHlok

Horizontal toggle clamp, Horizontal toggle clamp / horizontal foot



LRH

Bi-directional leadscrew, Bi-directional - 1 thread



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



PPOss

Pad eye on mounting plate oval, Stainless steel



APB_BOU

Protective cap, Safety cap



BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm



BTE

Universal tension arm, For normal applications




CHALss

Piano hinge, Stainless steel



ACLERP

Roller block for aluminium profile, Without guide rail

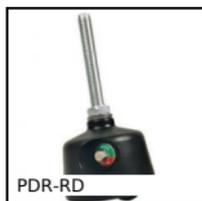

PDR-RD

Mounting feet with integrated castors, Offset castor



PP35

Worm and wheel gear reducer, from 2.20 to 4.10 Nm



DBL820

Idler for slat top chain, Ranges 820 and 815

Complementary products



BZY_SS

Stainless steel cylindrical elasto mount, Stainless steel



AZY

Cylindrical elasto mount, Steel



AZY_SS

Stainless steel cylindrical elasto mount, Stainless steel



CTZY

Diabolo shaped elasto mount, Steel