

Cylindrical elasto mount

Ste Stock

B-ZY

Male / female mounting

- Radial elasticity greater than axial elasticity
- Cylinder worked under compression or shearing
- Materials
core: Steel plates
cylinder: Rubber
- Hardness: NK 55-60 shore A
- Working temp: -40°C to +70°C



Uses

- Dampens sound and vibrations

Info.

- Not sold individually, please contact us for details
- Values for loads and rigidity are given as a guide only

From
size M3
upwards

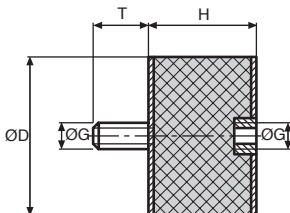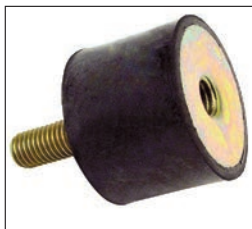

DISCOUNTS A

Qty	1+	6+	20+	40+	100+	200+
Disc.	List	-10%	-15%	-20%	-25%	On request

DISCOUNTS B

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØG	ØD	H	T	Compression		Shearing		Stock*	Price each 1 to 5
					stiffness (N/mm)	Max. load (N)	stiffness (N/mm)	Max. load (N)		
B-ZY3-8-8	M3	8	8	6	-	-	-	-	✓	A 4,03 €
B-ZY4-10-10	M4	10	10	10	48	43	10	35	✓	A 2,06 €
B-ZY4-10-15	M4	10	15	10	29	43	5	15	✓	A 2,19 €
B-ZY4-15-15	M4	15	15	10	67	95	15	35	✓	A 2,06 €
B-ZY4-15-20	M4	15	20	10	-	-	-	-	✓	A 2,16 €
B-ZY4-15-30	M4	15	30	15	-	-	-	-	✓	A 2,30 €
B-ZY5-15-15	M5	15	15	8	67	95	15	35	✓	A 2,16 €
B-ZY6-20-15	M6	20	15	18	130	170	24	60	✓	A 2,40 €
B-ZY6-20-20	M6	20	20	18	-	-	-	-	✓	A 2,39 €
B-ZY6-20-25	M6	20	25	18	61	170	11	60	✓	A 2,50 €
B-ZY6-25-15	M6	25	15	18	-	-	-	-	✓	A 2,73 €
B-ZY6-25-20	M6	25	20	18	130	280	30	95	✓	A 3,07 €
B-ZY6-25-25	M6	25	25	18	-	-	-	-	✓	A 3,17 €
B-ZY6-25-30	M6	25	30	18	71	280	19	95	✓	A 3,42 €
B-ZY8-30-15	M8	30	15	20	525	400	58	140	✓	A 3,75 €
B-ZY8-30-20	M8	30	20	20	235	400	42	140	✓	A 3,99 €
B-ZY8-30-25	M8	30	25	20	-	-	-	-	✓	A 4,33 €
B-ZY8-30-30	M8	30	30	20	113	400	28	140	✓	A 4,64 €
B-ZY8-30-40	M8	30	40	20	106	400	13	140	✓	A 5,21 €
B-ZY8-40-25	M8	40	25	23	-	-	-	-	✓	A 5,24 €
B-ZY8-40-30	M8	40	30	23	234	650	49	250	✓	A 5,89 €
B-ZY8-40-40	M8	40	40	23	147	650	23	250	✓	A 6,78 €
B-ZY10-40-30	M10	40	30	28	-	-	-	-	✓	A 6,34 €
B-ZY10-50-20	M10	50	20	28	857	1000	110	400	✓	A 7,68 €
B-ZY10-50-25	M10	50	25	28	-	-	-	-	✓	A 8,92 €
B-ZY10-50-30	M10	50	30	28	395	1000	73	400	✓	A 8,50 €
B-ZY10-50-40	M10	50	40	28	273	1000	58	400	✓	A 8,69 €
B-ZY10-50-45	M10	50	45	28	-	-	-	-	✓	A 8,90 €
B-ZY10-50-50	M10	50	50	28	210	1000	37	400	✓	A 9,51 €
B-ZY10-60-40	M10	60	40	28	-	-	-	-	-	A 12,82 €
B-ZY10-70-45	M10	70	45	28	-	-	-	-	-	A 19,25 €
B-ZY12-60-40	M12	60	40	33	-	-	-	-	✓	B 8,48 €
B-ZY12-75-25	M12	75	25	37	-	-	-	-	✓	B 0,00 €
B-ZY12-75-40	M12	75	40	37	735	2300	118	850	✓	B 0,25 €
B-ZY12-75-50	M12	75	50	37	530	2300	101	850	-	B 12,98 €
B-ZY12-75-55	M12	75	55	37	417	2300	78	850	-	B 13,52 €
B-ZY16-100-40	M16	100	40	41	2160	4200	283	1600	-	B 20,34 €
B-ZY16-100-55	M16	100	55	41	892	4200	145	1600	-	B 23,11 €
B-ZY16-100-60	M16	100	60	41	843	4200	142	1600	-	B 24,27 €
B-ZY16-100-75	M16	100	75	41	-	-	-	-	-	B 30,52 €

*Depending on availability - Dimensions in mm

Our other products



RDE-N

Sealing washer
Hygienic Usit®,
Stainless steel - Black
EPDM



PRES5HR

Manual workbench
press, Force up to
500kg




OP2

Mechanical digital
position indicator, 3
numbers



SCR

 Suction cup threaded
insert, Adaptor for
insert



PRF_TOOL

Assembly key for
aluminium profile,
Assembly key



BH02

Single housed bearing
assembly, Bearing
secured with circlips



ADL_M

Male eye bolt
conforms to DIN580,
Stainless steel



GG1

Ground spur gear,
Heat treated steel



KGS

Ballscrew, supplied by
the metre, Rolled
ballscrew, per metre



PCS62K

Chain sprocket with
hardened teeth,
15.875mm (DIN10B-1)



CHB

Worm and wheel gear
reducer, up to 41 Nm



T2

T type timing belt,
T2.5 Steel cored
polyurethane

Complementary products



BZY_SS

Stainless steel
cylindrical elasto
mount, Stainless steel



AZY

Cylindrical elasto
mount, Steel



AZY_SS

Stainless steel
cylindrical elasto
mount, Stainless steel



CTZY

Diabolo shaped elasto
mount, Steel