

PVC covered galvanised steel cable New

CAB/PVC

7x7 or 7x19 metal core

- Steel cable sold in rolls with anti-UV transparent PVC coating

- Braiding

> Ø5mm : 1 + 6 strands of 7 wires

Ø6mm > : 1 + 6 strands of 19 wires

Applications

- Plastic reel


- Outdoor applications

Option


- 100m reels

Info

- Remove the PVC protection on the area concerned if cable is being crimped

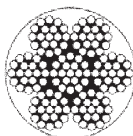

7x19

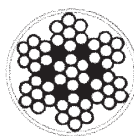

7x7

DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%		On request

Part N°	Cable Ø	ØExt	Type of braiding	Breaking strength (kg)	Length (metre)	Weight of reel (kg)	Price each 1 to 2
CAB2-25/PVC	2	3	7x7	280	25	0,57	28,03 €
CAB3-25/PVC	3	5	7x7	630	25	1,39	39,92 €
CAB4-25/PVC	4	6	7x7	1120	25	2,25	48,41 €
CAB6-25/PVC	6	8	7x19	2351	25	4,42	103,09 €

All dimensions in mm

Our other products



LACT_SS

Adjustable Stainless steel cam lever, Male



TB8

Cylindrical roller thrust bearing, Steel



NSKB

Drylin® Rail end cap, Rail end cap



PSPE20

Conical flexible shaft handle Ø20, Black PVC



SNG

Stainless/Polymer pillow block bearing, Cast iron - Split pillow



RPCtc

Swivel castor with central hole, Steel - Polyamide



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80



 
M0

Worm and wheel set, Non hardened steel



BOX-TOR-B

Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x



EPRF

High helix leadscrew, Flanged nut - up to 40mm per rotation



PRES

Manual workbench press accessory for PRES-3HR end



PLM-20SC

Threaded cylindrical magnet, With threaded hole

Complementary products



CCL

Standard wire thimble, Steel



CCLSS

Stainless steel wire thimble, Stainless steel



SCA

Flat cable clamp, Steel



SCA_SS

Stainless steel flat cable clamp, Stainless steel