

PVC covered galvanised steel cable New

CAB/PVC

7x7 or 7x19 metal core

- Steel cable sold in rolls with anti-UV transparent PVC coating

- Braiding

> Ø5mm : 1 + 6 strands of 7 wires

Ø6mm > : 1 + 6 strands of 19 wires

Applications

- Plastic reel


- Outdoor applications

Option


- 100m reels

Info

- Remove the PVC protection on the area concerned if cable is being crimped

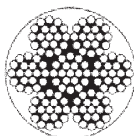

7x19

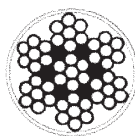

7x7

DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%		On request

Part N°	Cable Ø	ØExt	Type of braiding	Breaking strength (kg)	Length (metre)	Weight of reel (kg)	Price each 1 to 2
CAB2-25/PVC	2	3	7x7	280	25	0,57	28,03 €
CAB3-25/PVC	3	5	7x7	630	25	1,39	39,92 €
CAB4-25/PVC	4	6	7x7	1120	25	2,25	48,41 €
CAB6-25/PVC	6	8	7x19	2351	25	4,42	103,09 €

All dimensions in mm

Our other products



Gdal
Double universal joint
eco series, Low duty



BPF
Sheet steel flanged
bearing for light
loads, Sheet steel



GCH
Linear ball slide Eco
Range, economy
range



PCS62K
Chain sprocket with
hardened teeth,
15.875mm (DIN10B-1)



VBFP
Small 6 lobe threaded
handle - female,
Duroplast - Brass



WJUM20
Drylin® W bearing
block, Slide



BPM
Slotted spring plunger
with ball tip, Steel



CAP881
Side flexing slim slat
top chain stainless
steel, Narrow range
881



TBE12
Economic mini-table
with trapezoidal
leadscrew, 2kg



CHMR63
Worm and wheel gear
reducer, up to 196
Nm



LVT
Miniature motorised
actuator 4A, 4 amperes



BCM_TP
Modular cylindrical
brush, Tampico
bristles

Complementary products



CCL
Standard wire
thimble, Steel



CCLSS
Stainless steel wire
thimble, Stainless
steel



SCA
Flat cable clamp,
Steel



SCA_SS
Stainless steel flat
cable clamp, Stainless
steel