

PVC covered galvanised steel cable New

CAB/PVC

7x7 or 7x19 metal core

- Steel cable sold in rolls with anti-UV transparent PVC coating

- Braiding

> Ø5mm : 1 + 6 strands of 7 wires

Ø6mm > : 1 + 6 strands of 19 wires

Applications

- Plastic reel


- Outdoor applications

Option


- 100m reels

Info

- Remove the PVC protection on the area concerned if cable is being crimped

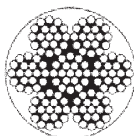

7x19

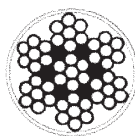

7x7

DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%		On request

Part N°	Cable Ø	ØExt	Type of braiding	Breaking strength (kg)	Length (metre)	Weight of reel (kg)	Price each 1 to 2
CAB2-25/PVC	2	3	7x7	280	25	0,57	28,03 €
CAB3-25/PVC	3	5	7x7	630	25	1,39	39,92 €
CAB4-25/PVC	4	6	7x7	1120	25	2,25	48,41 €
CAB6-25/PVC	6	8	7x19	2351	25	4,42	103,09 €

All dimensions in mm

Our other products



ZG0
Plastic spur gear,
Machined plastic
(delrin)



SSG0
Stainless steel spur
gear, Stainless steel
304L



CHML63
Worm and wheel gear
reducer, up to 138
Nm - Integrated
torque limiter



CLQ assortment
Assorted feeler strips



T5-10ECO
T type timing pulley,
Economy range - T5
aluminium



DCG
Suction cup, 2.5
bellows, nitrile



PSG25
Spur gear - precision
range, Case hardened
steel 20NCD2



SDA
Locking bolt support
bracket, Mounting
holes parallel to
locating bolt



DILC
Indexing plunger with
cam, with cam



VELM4
Screw-on base for
hook-and-loop strip,



CHAEpac
Square decorative
screwed hinges,



UCP
Cast iron pillow block
bearing, Cast iron

Complementary products



CCL
Standard wire
thimble, Steel



CCLSS
Stainless steel wire
thimble, Stainless
steel



SCA
Flat cable clamp,
Steel



SCA_SS
Stainless steel flat
cable clamp, Stainless
steel