

PVC covered galvanised steel cable

CAB/PVC

7x7 or 7x19 metal core

- Steel cable sold in rolls with anti-UV coating transparent PVC coating
- Braiding
 - > Ø5mm : 1 + 6 strands of 7 wires
 - Ø6mm > : 1 + 6 strands of 19 wires

Applications


- Plastic reel
- Outdoor applications

Option


- 100m reels

Info

- Remove the PVC protection on the area concerned if cable is being crimped

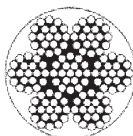

7x19

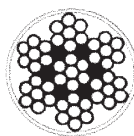

7x7

DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%	On request	

Part N°	Cable Ø	ØExt	Type of braiding	Breaking strength (kg)	Length (metre)	Weight of reel (kg)	Price each 1 to 2
CAB2-25/PVC	2	3	7x7	280	25	0,57	27,24 €
CAB3-25/PVC	3	5	7x7	630	25	1,39	38,79 €
CAB4-25/PVC	4	6	7x7	1120	25	2,25	47,04 €
CAB6-25/PVC	6	8	7x19	2351	25	4,42	100,17 €

All dimensions in mm

HPC

WEB
04/2019


www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



 VRC2
Retaining catch, Dual
sided



PEM
Magnetic label holder,
Flexible magnet
100mm



 
SK
Knob for clamping,
Star, rounded



WJRM
Drylin® W modular
guidance, Hybrid
bearings



PAP
Doorstop and handle,
Ergonomic handle



CXS
Circlip, external DIN
471



PSG08
Spur gear - precision
range, Case hardened
steel 20NCD2



CLB_T
Clamping lever -
male, Zamak



CHN_CHNSS
Straight long link
chain, Galvanised
steel



GRP2-14-C
Spring pin, splined
ISO 8744



EP
Spring pin, Spiralled
ISO 8750



NDS20
Double cross clamp,
Parallel

Complementary products



CCL
Wire thimble, Steel



CCLSS
Wire thimble,
Stainless steel



SCA
Cable clamp, Steel



SCA_SS
Cable clamp, Stainless
steel