

PVC covered galvanised steel cable New

CAB/PVC

7x7 or 7x19 metal core

- Steel cable sold in rolls with anti-UV transparent PVC coating

- Braiding

> Ø5mm : 1 + 6 strands of 7 wires

Ø6mm > : 1 + 6 strands of 19 wires

Applications

- Plastic reel


- Outdoor applications

Option


- 100m reels

Info

- Remove the PVC protection on the area concerned if cable is being crimped

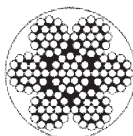

7x19

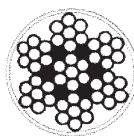

7x7

DISCOUNTS

Qty	1+	3+	10+
Disc.	Net -10%		On request

Part N°	Cable Ø	ØExt	Type of braiding	Breaking strength (kg)	Length (metre)	Weight of reel (kg)	Price each 1 to 2
CAB2-25/PVC	2	3	7x7	280	25	0,57	28,03 €
CAB3-25/PVC	3	5	7x7	630	25	1,39	39,92 €
CAB4-25/PVC	4	6	7x7	1120	25	2,25	48,41 €
CAB6-25/PVC	6	8	7x19	2351	25	4,42	103,09 €

All dimensions in mm

Our other products



HLA24

Right angle spiro bevel gearbox, Up to 78Nm



SSDB

Stainless steel bevel gear, 2:1



 
TPEpb

Castor for aluminium profile, Swivel with brake



FBL4004_K7

Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 -...



NK80

Drylin®N miniature guiding system, Width 80mm



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



WFRM

Flanged polymer nut, Polymer (Iglidur®) - 1 thread



PRF_ECL

Nut for aluminium profile, Stainless steel square nut with tab



PV2R

Adjustable suction-cup support, Increased grip



BABT

Hardened Stainless steel ball pin, Hardened stainless



CHAR5050_Z

Spring hinge for screw mounting, screwed



CTss

Universal joint, telescopic, Inox, Light duty

Complementary products



CCL

Standard wire thimble, Steel



CCLSS

Stainless steel wire thimble, Stainless steel



SCA

Flat cable clamp, Steel



SCA_SS

Stainless steel flat cable clamp, Stainless steel