

**New**

# Swaging sleeve for fitting cable

## To crimp a wire rope

**CABMA**

- Sleeve for fitting cable with metal core
- Complies with standard 13411-3 from CAB2-MA/B
- Temperature range: max 100 °C
- Material:  
Crude Aluminium

### Application

- For making retaining cables.
- For use with sheathed cable, remove the sheath along the length of the crimp to obtain a proper crimp.

#### Important:


- Not suitable for lifting
- Not suitable for stainless steel cable

### Info

- Cutting and crimping Tool CAB-TOOL

### Accessoires

- Pliers CABTOOL (tome 1 p.414)

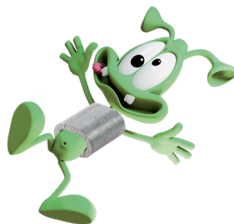**NEW!****Application example**

### DISCOUNTS

Qty	1+	3+	5+
Disc. Price	-10%	-10%	On request

Part number	For metal cable Diameter	For metal cable	Qty per lot	Price each 1 to 2
CAB1.5-MA/B	1.5	CAB1.5	100	25,65 €
CAB2-MA/B	2	CAB2	100	32,94 €
CAB2.5-MA/B	2.5	CAB2.5	100	47,54 €
CAB3-MA/B	3	CAB3	100	34,30 €
CAB4-MA/B	4	CAB4	100	59,43 €
CAB5-MA/B	5	CAB5	100	83,20 €

Dimensions in mm

## Our other products



BOX-TOR-B

Box set of Nitrile O-rings in nitrile, 20.38 x 1.78mm to 50.16 x 5.34



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



ERC

Quick fitting cable terminal, Eye version



ADL\_M

Male eye bolt conforms to DIN580, Stainless steel



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



PTA100ssEB

Articulated foot with sheet metal base Ø100, Articulated foot



CHB

Worm and wheel gear reducer, up to 22 Nm



SHN

Hexagonal nut DIN934, Steel (Class 6|8|9)



GCB880

Curved track for slat top chain, Ranges 880



GB-RA

Brass spur gear, Brass CuZn39Pb3



STRIPF

Sealing brush strip, 1m length



SSBRA

Stainless steel bevel gear, 1:1

## Complementary products



 
CABtool

Fitting cable tools, Crimping tools



CABtool

Fitting cable tools, Cutting tools



CAB

Galvanised steel cable, Galvanised steel