


- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)

 
 
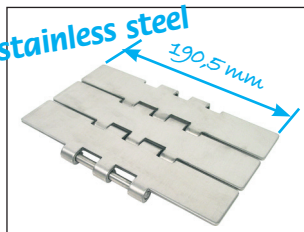


Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

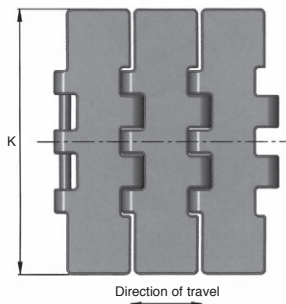

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

Our other products



 
M1

Worm and wheel set,
Hardened steel



VAB

Flanged nut for ball
screw, For VAB
ballscrew



RPP

Connecting plate for
RPP type timing belts,
RPP14



BLM

Spring loaded plunger
with ball tip, Stainless
steel body



CHTRB

Single and dual
output gearboxes, Up
to 53,1 Nm




BH01

Single housed
bearing, Bearing fitted
with adhesive



BABFCFO

Ball pin socket,
Mounting collar with a
round flange

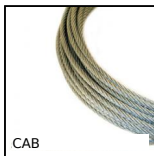

CAB

Stainless steel cable,
Stainless steel



BOX-TOR-A

Box set of Nitrile O-
rings in nitrile, 2.90 x



PCS75K

Chain sprocket with
hardened teeth,



PT882

Drive sprocket for slat
top chain, Range 882



RCX-6

Spherical tilt washer -
DIN6319, convex

Complementary products




PT821

Drive sprocket for slat
top chain, Ranges 821
and 805



PR821

 Idler sprocket for slat
top chain, Ranges 821
and 805



PRL

Wear strip for slat top
chain, L profile to be
clipped