


- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
  - Plates: polished cold-laminated stainless steel (30HRC min.)
  - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



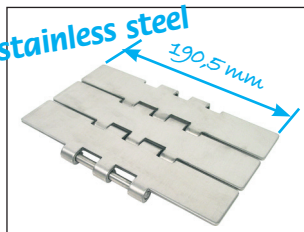


### Advantages

  - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

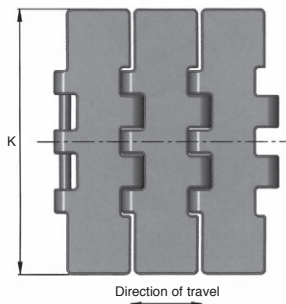

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

## Our other products



HK

Manual locking clamp,  
Manual locking clamp  
T



FR

Steel thread inserts,  
Steel



PRF\_CLIP\_22

Cable clip for  
aluminium profile, For  
electric and  
pneumatic cables



SLH-M

Nut for toggle clamp,  
Round ended nut for  
SLH/SLV clamp



ZG1

Plastic spur gear,  
Machined plastic  
(delrin)



T5P\_T10P

Connecting plate for T  
type timing belts, T10



PSG255

Spur gear - precision  
range, Stainless steel  
303




T10-BAR

T type tooth bar  
stock, T10



DOMI50

 Accessories, Plate



T0

Torsion spring,  
Stainless steel



STU

Stroke rotary bushing,  
Steel



BZY

Cylindrical elasto  
mount, Steel

## Complementary products




PT821

Drive sprocket for slat  
top chain, Ranges 821  
and 805



PR821

 Idler sprocket for slat  
top chain, Ranges 821  
and 805



PRL

Wear strip for slat top  
chain, L profile to be  
clipped