

- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)






Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

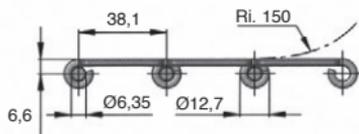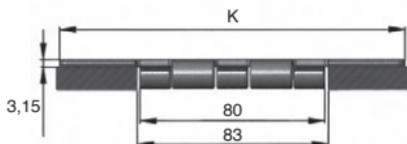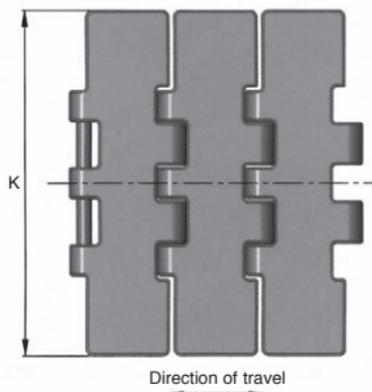

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

Our other products



CHTRP

Single and dual output gearboxes, Up to 87,3Nm



AC

Strike for toggle latch, 15mm



NCT

Square tube connector, Fixed angle



CFS

Miniature cam follower, Miniature angle



BVR

Adjustable screw stop, Steel



SA_SAKH

Housing for linear bearing, Closed - light load



BLH50

Right angled gearbox, from 7.70 to 20 Nm



SSG1

Stainless steel spur gear, Stainless steel 304L



SVT30

Screwjack with travelling screw, with



M2

Wormwheel, Bronze



STC

Shock Absorber - stop collar, Universal



LVT

Miniatur motorised actuator 2A, 2 amperes

Complementary products




PT821

Drive sprocket for slat top chain, Ranges 821 and 805



PR821

Idler sprocket for slat top chain, Ranges 821 and 805

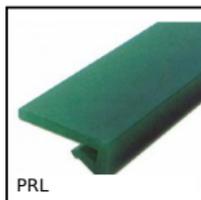

PRL

Wear strip for slat top chain, L profile to be clipped