


- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)

 
 
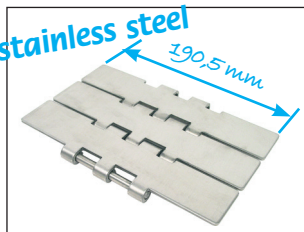


Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

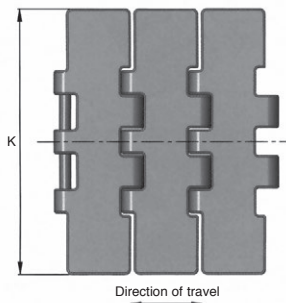

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

Our other products



BUH77
Motor-gearbox 12V
and 24V DC, from 0.1
to 2 Nm



 
BOX-WM
Box set of washer -
DIN125, Box set of
steel washers



ACLRP
Wheel for aluminium
profile, Integrated
bearing



CDR
Retaining cable for
ball pin, Retaining
cable



RPP
Connecting plate for
RPP type timing belts,
RRP5



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT5




H0
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



RLXAC8
Free roller, Steel



 YG3
HEAVY DUTY spur
gear, Steel 35NCD6



H1
Crossed helical gear
crossed axis at 90°



SH0
Parallel axis helical
gear, Steel 20NCD2



RPC
Wheel, Polyamide


Complementary products



PT821
Drive sprocket for slat
top chain, Ranges 821
and 805



 PR821
Idler sprocket for slat
top chain, Ranges 821
and 805



PRL
Wear strip for slat top
chain, L profile to be
clipped