


- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
  - Plates: polished cold-laminated stainless steel (30HRC min.)
  - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



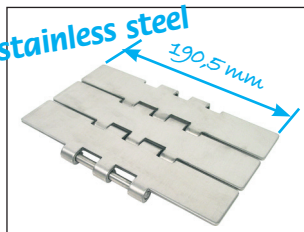


### Advantages

  - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

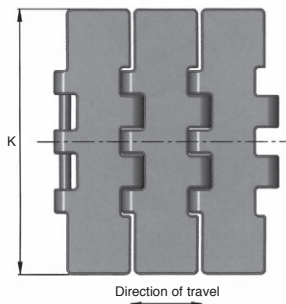

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

## Our other products



PSEC  
Security pull handle,  
Thermoplastic




PR105  
Articulated foot Ø103,  
Ø 103



PSG05  
Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6



 BH01  
Single housed  
bearing, Bearing fitted  
with adhesive



QNU  
Single row cylindrical  
roller bearing, Free  
inner ring



RPP  
Connecting plate for  
RPP type timing belts,  
RPP8



HBM  
Adjustment bushing  
for half-rail guide,  
Adjustment bushing



AT5courroie  
AT type timing belt,  
AT5 Steel cored  
polyurethane



LWL  
Linear ball slide -  
Stainless steel balls,  
Chariot - from 514 N



AT5M AT10M  
AT type timing belt  
per metre, AT10 Steel  
cored polyurethane



PLC\_PLT  
Magnetic stud with  
central hole, With  
central hole



CHTRP  
Single and dual  
output gearboxes, Up  
to 9,1 Nm


## Complementary products



PT821  
Drive sprocket for slat  
top chain, Ranges 821  
and 805



 PR821  
Idler sprocket for slat  
top chain, Ranges 821  
and 805



PRL  
Wear strip for slat top  
chain, L profile to be  
clipped