


- Main applications are in bottling plants and for moving hard products
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)

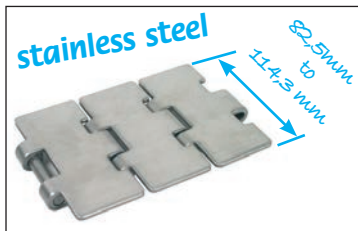


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

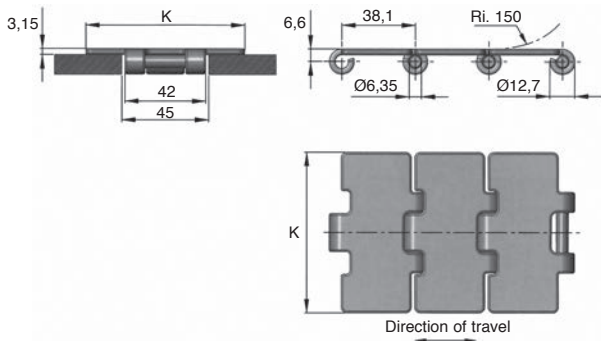

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	119,80 €
CAP815-114/SS	114,3	3048	10400	3,40	174,29 €

Dimensions in mm

Our other products



TPEpbd

Castor for aluminium profile, Swivel with brake



PTMR

Telescopic furniture foot, threaded stud



ACLALF

Adjustable foot for aluminium profile, Ideal for workstations



PGMT

Pull handle, Steel



SRG

Adjustable latch clamp with strike plate, Stroke from 78mm to 90mm



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg



ACLBMC

Detector support for aluminium profile, Sensor holder



RBGpl

Swivel castor with plate, Steel - grey rubber



BABA

Ball pin lifting ring, Steel



TSM_T10M

T type timing belt per metre, T5 Steel cored polyurethane



DIA

Ring operated locking bolt, with ring



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW

Complementary products



PR820

Idle sprocket for slat top chain, Ranges 820 and 815



DBL820

Idle for slat top chain, Ranges 820 and 815



CAP820

Slim slat top chain acetal, Narrow straight range 820



GALRUB

60mm rubber wheel for conveyor belt, Rubber