


- **Main applications are in bottling plants and for moving hard products**
- Smooth surface with no backlash
- Materials:
  - Plates: polished cold-laminated stainless steel (30HRC min.)
  - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)

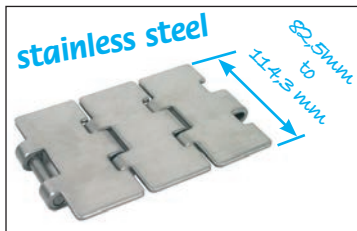


### Advantages

- Wide field of applications

### Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

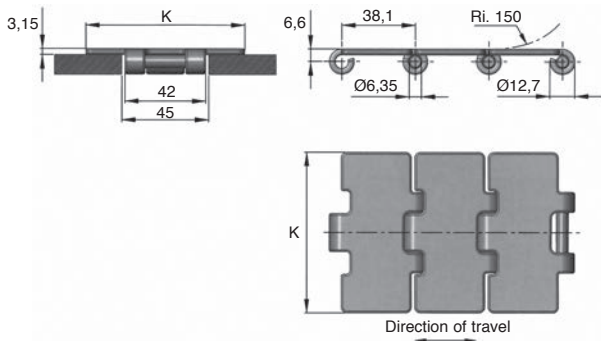

### DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	119,80 €
CAP815-114/SS	114,3	3048	10400	3,40	174,29 €

Dimensions in mm

## Our other products



OPFL\_OPPM  
Numerical counter accessories, Locking clamp



G2  
Steel spur gear, Steel 20NCD2



P30  
Worm and wheel gear reducer, up to 8.80 Nm



PRF19\_E  
Bracket for aluminium profile, PRF19 to PRF45



RPCtc  
Swivel castor with central hole, Steel - Polyamide - with double brake



HTD5M\_15  
HTD Heavy duty timing pulley, HTD5 Aluminium



HLC24  
Right angle spiro bevel gearbox, Up to 78Nm



SH0  
Parallel axis helical gear, Steel 20NCD2



CSS  
Spherical bushing, Steel / self lubricating



RAM30  
Manual bevel gearbox, Bevel



CHAC4040SS  
Square hinge with riveted pin, drilled,



LVT  
Miniatur motorised actuator 1A, 1 amper

## Complementary products



PR820  
Idler sprocket for slat top chain, Rangs 820 and 815



DBL820  
Idler for slat top chain, Ranges 820 and 815



CAP820  
Slim slat top chain acetel, Narrow straight range 820



GALRUB  
60mm rubber wheel for conveyor belt, Rubber