


- **Main applications are in bottling plants and for moving hard products**
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)

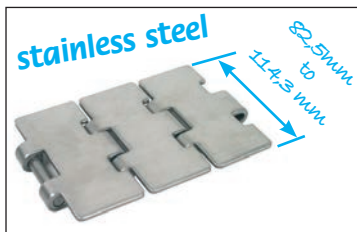


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

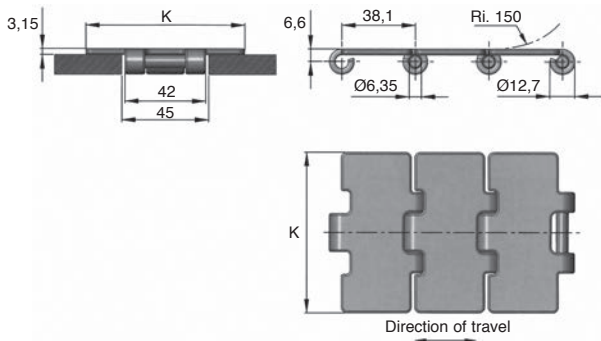

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	119,80 €
CAP815-114/SS	114,3	3048	10400	3,40	174,29 €

Dimensions in mm

Our other products



AT5-25ECO

AT type timing pulley,
Economy range - AT5
aluminium



PGB

Accessory-holder for
aluminium profile,
Tool holder




CHN_CHNSS

Straight long link
stainless steel chain,
Stainless steel



RJUM05

 Drylin R® linear
bearing housing,
Closed - Slim



LVTMFC

Device for controlling
limit switches, For
mini-actuator LVT



CHTRP

Single and dual
output gearboxes, Up
to 87,3 Nm



SHNbr

Hexagonal nut
DIN934, Brass



PTA40ssEB

Articulated foot with
sheet metal base
Ø40, Ø 40



LRR

Spring loaded latch,
Spring loaded latch



ABL100000

Antistatic brush, For
sensitive surfaces



M2

Worm and wheel set,
Machined plastic
(delrin)



PTKss

Foot for the food
industry, Stainless
steel - 3-A standard

Complementary products



PR820

Idler sprocket for slat
top chain, Rangs 820
and 815



DBL820

Idler for slat top
chain, Ranges 820
and 815



CAP820

Slim slat top chain
acetal, Narrow
straight range 820



GALRUB

60mm rubber wheel
for conveyor belt,
Rubber