


- Main applications are in bottling plants and for moving hard products
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)

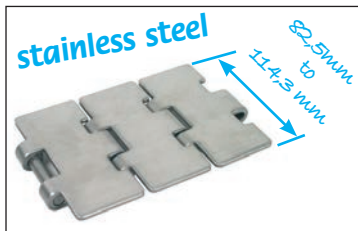


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

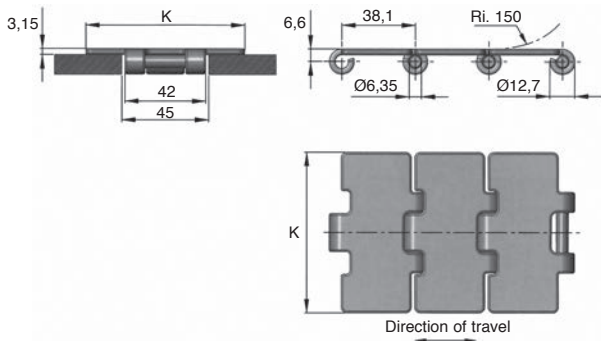

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	119,80 €
CAP815-114/SS	114,3	3048	10400	3,40	174,29 €

Dimensions in mm

Our other products



MBF

Threaded blocking clamp, Threaded locking clamp



HW_HT

Half-rail guide, Rail



G-ECO

Eco range Spur gear, Steel C45



ZHG5

Plastic spur gear, Machined plastic (delrin)



 
SUPss

Self-centering clamping hub stainless steel, Without locknut



HBM

Adjustment bushing for half-rail guide, Adjustment bushing



PF40NM

Worm and wheel gear reducer, up to 18 Nm



NPCR

Adjustable cell support, Adjustable



DKN

Bellows coupling Gerwah®, from 0.4 to 10Nm



BPHRF

Ball transfer unit housed spring loaded, High



CHM110

Worm and wheel gear reducer, up to 980 Nm



PO

Pull handle - Multi-sector, Tapped recessed insert

Complementary products



PR820

Idle sprocket for slat top chain, Ranges 820 and 815



DBL820

Idle sprocket for slat top chain, Ranges 820 and 815



CAP820

Slim slat top chain acetal, Narrow straight range 820



GALRUB

60mm rubber wheel for conveyor belt, Rubber