


- **Main applications are in bottling plants and for moving hard products**
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)

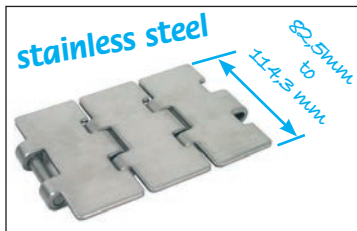


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

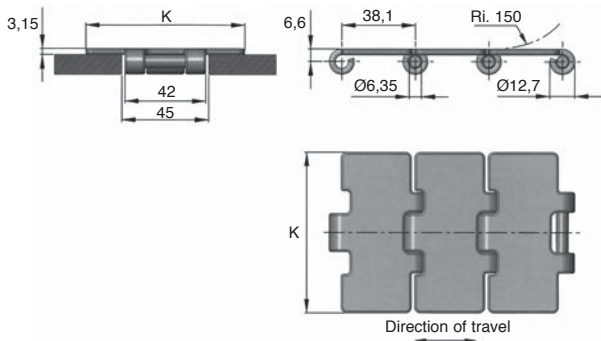

DISCOUNTS

Qty	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	119,80 €
CAP815-114/SS	114,3	3048	10400	3,40	174,29 €

Dimensions in mm

Our other products



Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



Right angled gearbox, bored shafts, up to 30 Nm



Steel thread inserts, Steel



Stainless steel bevel gear, 2:1



Automatic chain tensioner, With wide guide



Vertical toggle clamp, Vertical toggle clamp / vertical foot



Miniature cam follower, Miniature



 
Shaft support for aluminium profile, Linear guide shaft



Fixed castor with plate, Steel - Polyamide



Offset spur gear reducer, from 0.78 to 3.70 Nm



Self-lubricating blanks, Ferrous alloy (FP20)



Hexagonal nut DIN934, A2 Stainless steel

Complementary products



Idler sprocket for slat top chain, Ranges 820 and 815



Idler for slat top chain, Ranges 820 and 815



Slim slat top chain acetal, Narrow straight range 820



60mm rubber wheel for conveyor belt, Rubber