


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
  - Plates: low friction acetal
  - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

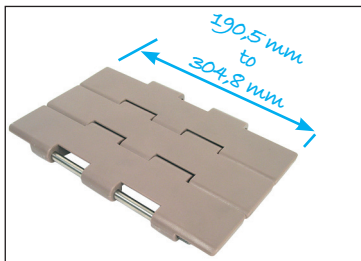




### Advantages

  - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

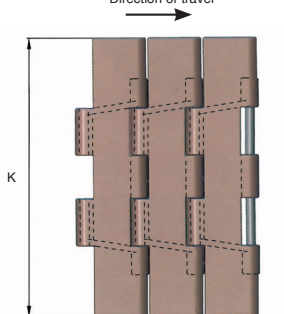

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

## Our other products



P30  
Worm and wheel gear reducer, up to 8.80 Nm



CDPC  
Flanged drill bushing, Steel



VRBS  
Folding lifting ring for welding, Folding - for welding



HCV  
V-rail guidance Simple Select® system, on rail




R\_RR  
Narrow spur rack, Steel



TBEBASE10  
Economic mini-table with trapezoidal leadscrew, 1kg



 PRF\_BASE  
Base plate for aluminium profile, Base plate



PRF LIS  
Door seal for aluminium profile, Black NBR



BOX-NINA  
Self locking nut - DIN985, Box set of steel nuts



RURp  
Fixed castor with plate, Polyurethane - Aluminium rim (Free



SHNbr  
Hexagonal nut DIN934, Brass



GGP  
Male wing knob, Technopolymer with stainless steel spindle


## Complementary products



PT821  
Drive sprocket for slat top chain, Ranges 821 and 805



 PR821  
Idler sprocket for slat top chain, Ranges 821 and 805



PRL  
Wear strip for slat top chain, L profile to be clipped