


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
 - Plates: low friction acetal
 - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

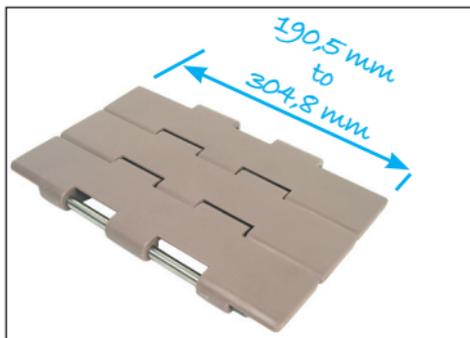

 


Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

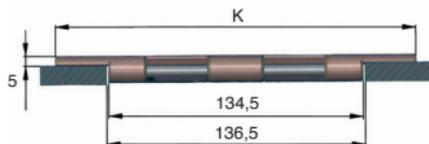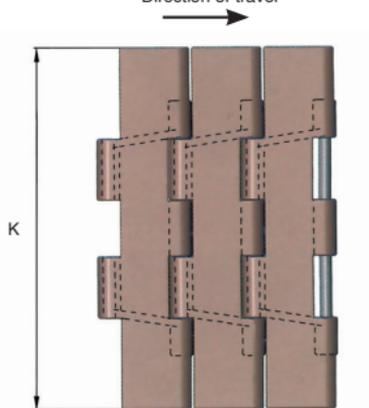

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

Our other products



SH2

Parallel axis helical gear, Machined plastic (delrin)



HSE-HSB

Hexagonal spacer, Steel



CM0

Male rod ends DIN ISO12240-4, Steel / bronze



BABA

Ball pin lifting ring, Steel



PR125

Articulated foot Ø123, Ø 123



AT5M AT10M

AT type timing belt per metre, AT5 Steel cored polyurethane



M0

Worm and wheel set, Non hardened steel



ADL

Eye bolt high resistance, alloy steel



SSDB

Stainless steel bevel gear, 2:1



ALIDRP240

24V DC power supply, 10 A



CHB

Reaction arm, CHB gear reducers reaction arm



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel

Complementary products




PT821

Drive sprocket for slat top chain, Ranges 821 and 805



PR821

Idler sprocket for slat top chain, Ranges 821 and 805

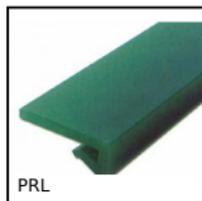

PRL

Wear strip for slat top chain, L profile to be clipped