


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
 - Plates: low friction acetal
 - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

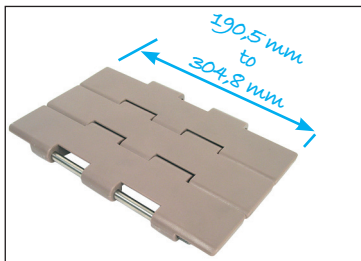

 
 

Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

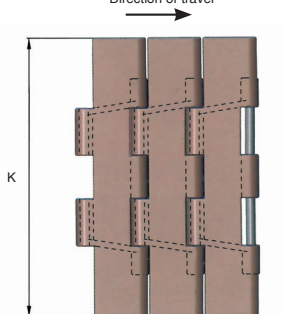

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

Our other products



HRV

V-rail guidance
Simple Select®
system, Rail with
carriage



DILC

Indexing plunger with
cam, with cam



GTC

Belt tensioner, For
standard applications



FHCSS

Countersunk screw,
Stainless steel A2 -
DIN 7991



PRF4545

Standard stainless
steel profile, 45 x 45
mm




BLHB20

Right angled gearbox,
bored shafts, up to
1.77 Nm



PARF80

 Pressed steel base
rigid foot, Swivelling -
Ø80



RIMtce

Locking castor, with
central hole



RVM14

Manual worm and
wheel gearbox,
Worm/wheel



 
MEB

Moulded plastic bevel
gear (nylon), 1:1



PLS

Cylindrical spacer,
Stainless steel 303



NRR

Adjustable support
clamp, Adjustable
support clamp

Complementary products




PT821

Drive sprocket for slat
top chain, Ranges 821
and 805



PR821

 Idler sprocket for slat
top chain, Ranges 821
and 805



PRL

Wear strip for slat top
chain, L profile to be
clipped