


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
  - Plates: low friction acetal
  - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

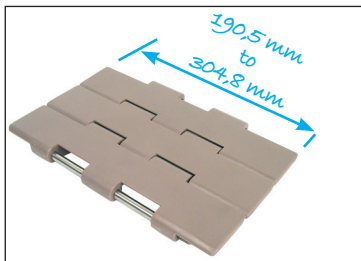




### Advantages

  - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

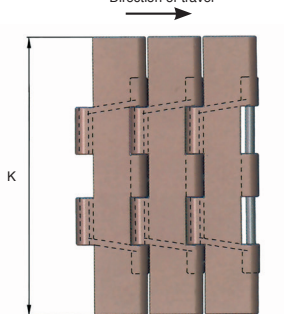

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

 
Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

## Our other products



Spherical tilt washer -  
DIN6319, convex



Arm with folding  
rotating handle,




Belt tensioner, For  
standard applications



Worm and wheel gear  
reducer, up to 118  
Nm



Asynchronous AC  
motor , 0.09kW

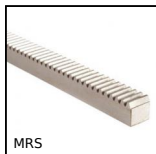

Stainless steel metric  
section rack, Stainless  
steel



Machined plastic  
bevel gear , 2:1



Hexagonal headed  
screw with collar  
Hygienic Usit® ,  
Stainless steel



 
Weld-on hinge with  
flat end, Stainless



Connecting plate for T  
type timing belts, T10



Flanged polymer  
bush, Food grade



Screw-in garnet  
hinge, Screw-on


## Complementary products



 Drive sprocket for slat  
top chain, Ranges 821  
and 805



Idler sprocket for slat  
top chain, Ranges 821  
and 805



Wear strip for slat top  
chain, L profile to be  
clipped